

Maintain Signal Transmission in High-Noise Environments

Upgraded Shielded Industrial Ethernet Cordsets from Lumberg Automation

Achieve better performance in harsh environments – at a competitive price – with shielded, 4-pair industrial Ethernet cordsets.



Proven Design – prevent noise from hurting signal transfer speeds with extra immunity in high EMI and RFI locations from Belden's patented Bonded-Pair technology



Elevated Performance – upgrade to robust, highly-flexible, sunlight, and oil resistant TPE jacketing, which holds up far better to flexing and abrasion than PVC-jacketed cordsets




Enhanced Integration and Safety – meet the requirements of high-powered machinery in code-regulated environments with 600V AWM-rated cordsets

Benefits Multiple Industrial Markets

- General Manufacturing
- Automotive
- Food and Beverage
- Machine Building

Product Features

- 4-pair (8 conductors)
- TPE jacket with M12 (Male, Female, & Female Bulkhead) and RJ45 connector options
- Belden bonded, twisted-pair construction
- 600V AWM rating
- Cat5e for 10, 100 and Gigabit Ethernet speeds
- Small, flat-laying form factor

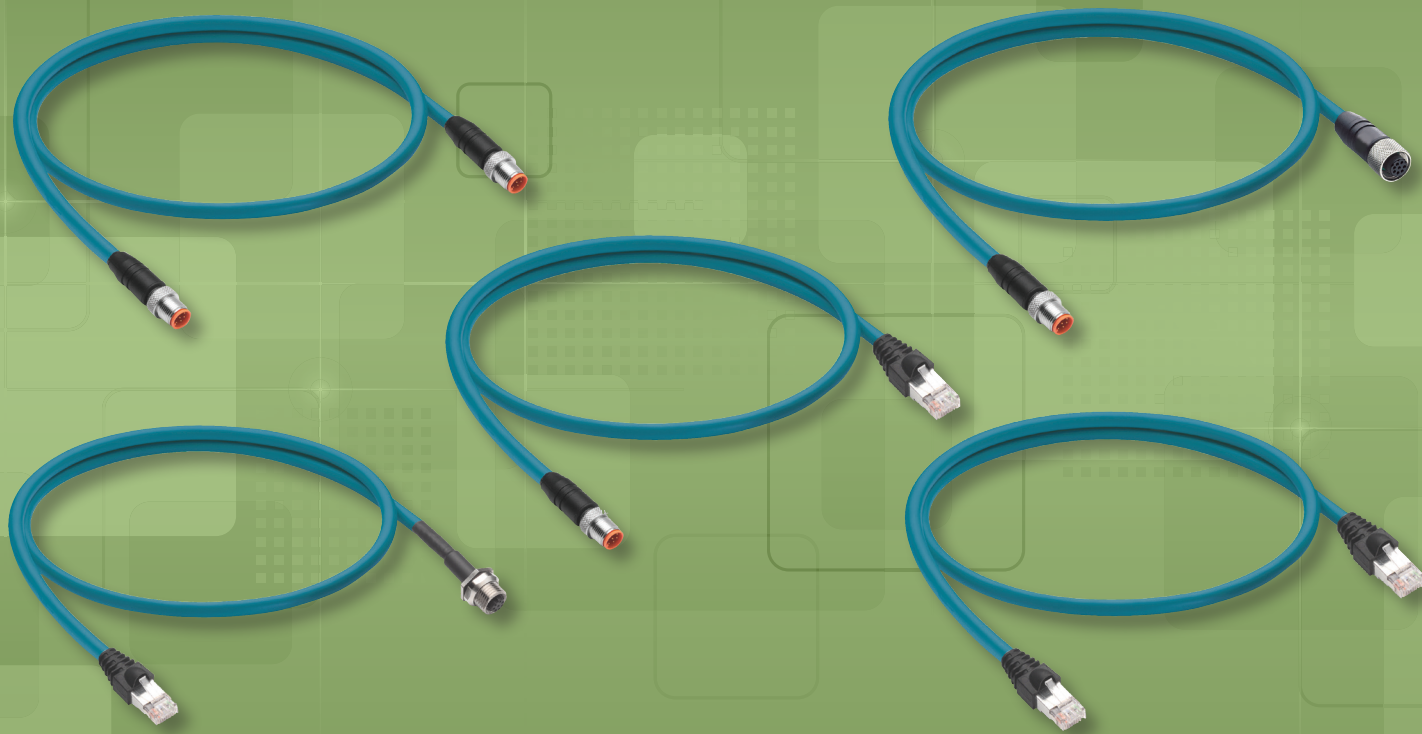

Shielded, TPE-jacketed and 600V AWM-rated, these 4-pair versions of our popular 2-pair Industrial Ethernet cordsets are ideal for use in harsh, high-noise environments.

Be certain.
Belden.

600V Ethernet Cordsets

Shielded Bonded-Pair, 4-Pair, Industrial, 24AWG, Stranded, High Flex, Teal, TPE Jacket

M12 Male Straight -M12 Male Straight		M12 Male Straight -RJ45 Male		RJ45 Male-RJ45 Male		M12 Male Straight-M12 Female Straight	
							
Part Number	Description	Part Number	Description	Part Number	Description	Part Number	Description
900016027	0985 856 100/0.3M	900016056	0985 856 103/0.3M	900016090	0985 856 500/0.3M	900016050	0985 856 102/1M
900016028	0985 856 100/0.6M	900016057	0985 856 103/0.6M	900016091	0985 856 500/0.6M	900016051	0985 856 102/2M
900016029	0985 856 100/1M	900016058	0985 856 103/1M	900016092	0985 856 500/1M	900016052	0985 856 102/5M
900016030	0985 856 100/1.5M	900016059	0985 856 103/1.5M	900016093	0985 856 500/1.5M	900016053	0985 856 102/10M
900016031	0985 856 100/2M	900016060	0985 856 103/2M	900016094	0985 856 500/2M	900016054	0985 856 102/15M
900016032	0985 856 100/2.5M	900016061	0985 856 103/2.5M	900016095	0985 856 500/2.5M	900016055	0985 856 102/20M
900016034	0985 856 100/3M	900016062	0985 856 103/3M	900016096	0985 856 500/3M		
900016035	0985 856 100/4M	900016064	0985 856 103/4M	900016098	0985 856 500/4M	M12 Female Bulkhead-RJ45 Male	
900016036	0985 856 100/5M	900016065	0985 856 103/5M	900016099	0985 856 500/5M		
900016037	0985 856 100/6M	900016066	0985 856 103/6M	900016100	0985 856 500/6M		
900016038	0985 856 100/8M	900016067	0985 856 103/8M	900016101	0985 856 500/8M		
900016039	0985 856 100/10M	900016068	0985 856 103/10M	900016102	0985 856 500/10M		
900016040	0985 856 100/12M	900016069	0985 856 103/12M	900016103	0985 856 500/12M		
900016041	0985 856 100/15M	900016070	0985 856 103/15M	900016104	0985 856 500/15M		
900016042	0985 856 100/20M	900016071	0985 856 103/20M	900016105	0985 856 500/20M		
900016043	0985 856 100/25M	900016072	0985 856 103/25M	900016106	0985 856 500/25M		
900016044	0985 856 100/30M	900016073	0985 856 103/40M	900016107	0985 856 500/30M	900016078	0985 856 104/0.3M
900016045	0985 856 100/40M	900016074	0985 856 103/50M	900016108	0985 856 500/35M	900016079	0985 856 104/0.6M
900016046	0985 856 100/50M	900016075	0985 856 103/60M	900016109	0985 856 500/40M	900016080	0985 856 104/1M
900016047	0985 856 100/60M	900016076	0985 856 103/70M	900016110	0985 856 500/45M	900016081	0985 856 104/1.5M
900016048	0985 856 100/70M	900016077	0985 856 103/80M	900016111	0985 856 500/50M	900016082	0985 856 104/2M
900016049	0985 856 100/80M			900016112	0985 856 500/55M	900016083	0985 856 104/2.5M
Stock Item Other lengths available on request				900016113	0985 856 500/60M	900016084	0985 856 104/3M
				900016114	0985 856 500/65M	900016085	0985 856 104/4M
				900016115	0985 856 500/70M	900016086	0985 856 104/5M
				900016116	0985 856 500/75M	900016087	0985 856 104/6M
				900016117	0985 856 500/80M	900016088	0985 856 104/10M
				900016089	0985 856 104/15M		

www.belden.com | 1-800-BELDEN1

Belden, Belden Sending All The Right Signals, Hirschmann, GarrettCom, Tofino Security, Lumberg Automation and the Belden logo are trademarks or registered trademarks of Belden Inc. or its affiliated companies in the United States and other jurisdictions. Belden and other parties may also have trademark rights in other terms used herein.

©Copyright 2018, Belden Inc.

856-ETHERNET-CORDSET-CUSTOMER-FLYER_SF_ICOS_LUM_0418_ENG

**Be certain.
Belden.**