


Direct Connect

with REVConnect



The Field Mountable REVConnect Plug is the answer to your IoT and AV needs. One reliable, easy, versatile termination process is all that's required for your building security systems, LED lighting and sensors, wireless access points, HVAC, digital signage, audio mixing consoles, and more.

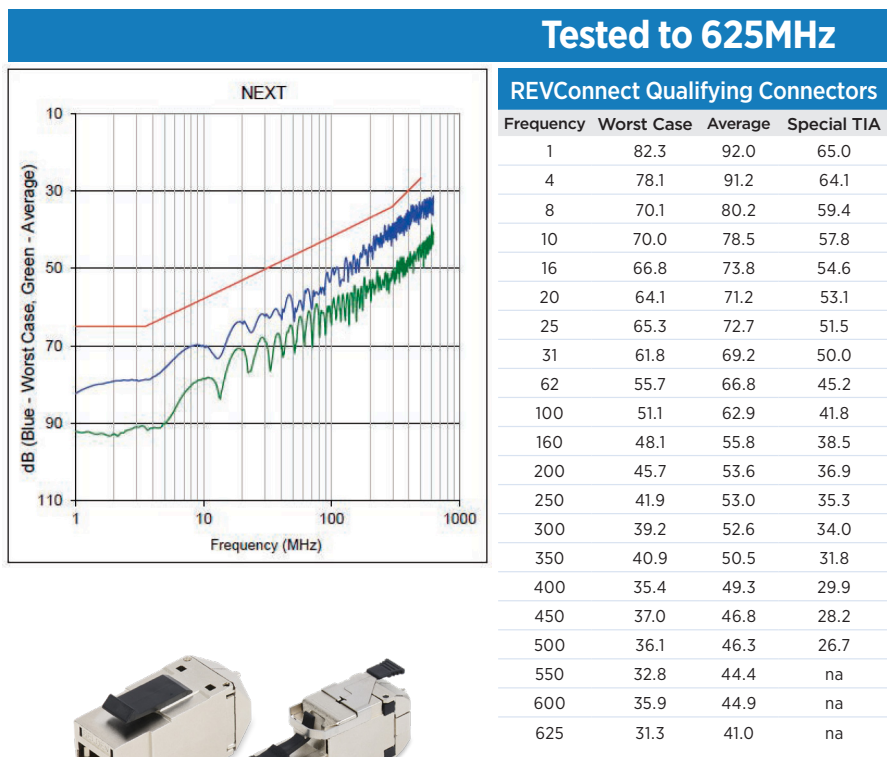

- **Saves money**
Eliminates the jack, box, and patch cord assembly needed to plug into devices
- **Saves Time**
Single termination process for every application
- **Peace of Mind**
Strong, Belden warranted performance for Networking and HDBaseT
- **PoE Ready**
Supports devices requiring up to 100W power
- **Strongest IL Performance**
Direct use of horizontal cable eliminates patch cord derating

For more information, call
1.800.BELDEN.1 (1.800.235.3361) or
visit [belden.com/products/revconnect](https://www.belden.com/products/revconnect)

Ordering Information

REVConnect 10GX Category 6A

Description	Elec White ●	Black ●	Gray ●	Ivory ●	Almond ●
REVConnect 10GX Jack - Single Pack	RVAMJKUEW-S1	RVAMJKUBK-S1	RVAMJKUGY-S1	RVAMJKUIV-S1	RVAMJKUAL-S1
REVConnect 10GX Jack - Bulk Pack	RVAMJKUEW-B24	RVAMJKUBK-B24	RVAMJKUGY-B24	RVAMJKUIV-B24	RVAMJKUAL-B24




Description	Brown ●	Red ●	Orange ●	Yellow ●	Green ●	Blue ●	Purple ●
REVConnect 10GX Jack - Single Pack	RVAMJKUBR-S1	RVAMJKURD-S1	RVAMJKUOR-S1	RVAMJKUYL-S1	RVAMJKUGN-S1	RVAMJKUBL-S1	RVAMJKUPR-S1
REVConnect 10GX Jack - Bulk Pack	RVAMJKUBR-B24	RVAMJKURD-B24	RVAMJKUOR-B24	RVAMJKUYL-B24	RVAMJKUGN-B24	RVAMJKUBL-B24	RVAMJKUPR-B24

Description	Brown TIA ●	Red TIA ●	Orange TIA ●	Yellow TIA ●	Green TIA ●	Blue TIA ●	Purple TIA ●
REVConnect 10GX Jack - Single Pack	RVAMJKUTN-S1	RVAMJKUTR-S1	RVAMJKUTO-S1	RVAMJKUTY-S1	RVAMJKUTG-S1	RVAMJKUTB-S1	RVAMJKUTP-S1
REVConnect 10GX Jack - Bulk Pack	RVAMJKUTN-B24	RVAMJKUTR-B24	RVAMJKUTO-B24	RVAMJKUTY-B24	RVAMJKUTG-B24	RVAMJKUTB-B24	RVAMJKUTP-B24

REVConnect CAT6+ Category 6

Description	Elec White ●	Black ●	Gray ●	Ivory ●	Almond ●
REVConnect CAT6+ Jack - Single Pack	RV6MJKUEW-S1	RV6MJKUBK-S1	RV6MJKUGY-S1	RV6MJKUIV-S1	RV6MJKUAL-S1
REVConnect CAT6+ Jack - Bulk Pack	RV6MJKUEW-B24	RV6MJKUBK-B24	RV6MJKUGY-B24	RV6MJKUIV-B24	RV6MJKUAL-B24

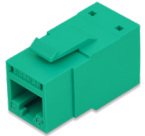

Description	Brown ●	Red ●	Orange ●	Yellow ●	Green ●	Blue ●	Purple ●
REVConnect CAT6+ Jack - Single Pack	RV6MJKUBR-S1	RV6MJKURD-S1	RV6MJKUOR-S1	RV6MJKUYL-S1	RV6MJKUGN-S1	RV6MJKUBL-S1	RV6MJKUPR-S1
REVConnect CAT6+ Jack - Bulk Pack	RV6MJKUBR-B24	RV6MJKURD-B24	RV6MJKUOR-B24	RV6MJKUYL-B24	RV6MJKUGN-B24	RV6MJKUBL-B24	RV6MJKUPR-B24

Description	Brown TIA ●	Red TIA ●	Orange TIA ●	Yellow TIA ●	Green TIA ●	Blue TIA ●	Purple TIA ●
REVConnect CAT6+ Jack - Single Pack	RV6MJKUTN-S1	RV6MJKUTR-S1	RV6MJKUTO-S1	RV6MJKUTY-S1	RV6MJKUTG-S1	RV6MJKUTB-S1	RV6MJKUTP-S1
REVConnect CAT6+ Jack - Bulk Pack	RV6MJKUTN-B24	RV6MJKUTR-B24	RV6MJKUTO-B24	RV6MJKUTY-B24	RV6MJKUTG-B24	RV6MJKUTB-B24	RV6MJKUTP-B24

REVConnect CAT5E Category 5e

Description	Elec White ●	Black ●	Gray ●	Ivory ●	Almond ●
REVConnect CAT5E Jack - Single Pack	RV5MJKUEW-S1	RV5MJKUBK-S1	RV5MJKUGY-S1	RV5MJKUIV-S1	RV5MJKUAL-S1
REVConnect CAT5E Jack - Bulk Pack	RV5MJKUEW-B24	RV5MJKUBK-B24	RV5MJKUGY-B24	RV5MJKUIV-B24	RV5MJKUAL-B24



Description	Brown ●	Red ●	Orange ●	Yellow ●	Green ●	Blue ●	Purple ●
REVConnect CAT5E Jack - Single Pack	RV5MJKUBR-S1	RV5MJKURD-S1	RV5MJKUOR-S1	RV5MJKUYL-S1	RV5MJKUGN-S1	RV5MJKUBL-S1	RV5MJKUPR-S1
REVConnect CAT5E Jack - Bulk Pack	RV5MJKUBR-B24	RV5MJKURD-B24	RV5MJKUOR-B24	RV5MJKUYL-B24	RV5MJKUGN-B24	RV5MJKUBL-B24	RV5MJKUPR-B24

Description	Brown TIA ●	Red TIA ●	Orange TIA ●	Yellow TIA ●	Green TIA ●	Blue TIA ●	Purple TIA ●
REVConnect CAT5E Jack - Single Pack	RV5MJKUTN-S1	RV5MJKUTR-S1	RV5MJKUTO-S1	RV5MJKUTY-S1	RV5MJKUTG-S1	RV5MJKUTB-S1	RV5MJKUTP-S1
REVConnect CAT5E Jack - Bulk Pack	RV5MJKUTN-B24	RV5MJKUTR-B24	RV5MJKUTO-B24	RV5MJKUTY-B24	RV5MJKUTG-B24	RV5MJKUTB-B24	RV5MJKUTP-B24

REVConnect 10GX, CAT6+, CAT5E Shielded Jacks, Shielded and Unshielded Plugs

Package Size	10GX Shielded Jacks	10GX Shielded Jacks (large core)	CAT6+ Shielded Jacks	CAT5E Shielded Jacks	10GX Shielded Plugs	10GX Shielded Plugs (large core)	10GX UTP Plugs
Single Pack	RVAMJKSME-S1	RVAEJKSME-S1	RV6MJKSME-S1	RV5MJKSME-S1	RVAFPSME-S1	RVAEFPSME-S1	RVAFPUBK-S1
Bulk Pack (24 Modules)	RVAMJKSME-B24	RVAEJKSME-B24	RV6MJKSME-B24	RV5MJKSME-B24	RVAFPSME-B24	RVAEFPSME-B24	RVAFPUBK-B24

REVConnect Tool and Accessories

Universal Termination Tool	Tool Spare Blade Set	Cable Prep Tool Replacement	Tool Belt Clip	Dust Caps for Jacks	Icons for Jacks	Bulk Pack of REVConnect Cores	Bulk Pack of REVConnect Large Cores
RVUTT01	RVUTB01	RVUCT01	RVUTC01	RVUDCXX-B24	RVUICXX-B24	RVUCOEW-B50	RVUECOGY-B50
Includes tool, cable prep insert, and spare blade set	Optional extra set of blades with Allen key included	Optional cable prep tool replacement insert	Optional belt clip for universal tool	Optional dust caps for all jacks; XX is color code, pack of 24	Optional icons for all jacks; XX is color code, pack of 24	Bulk pack of 50 cable managers and caps for cables 0.9 mm up to 1.3 mm in diameter	Bulk pack of 50 cable managers and caps for cables 1.3 mm up to 1.45 mm in diameter

Color codes: AL (almond), BK (black), BL (blue), BR (brown), EW (electric white), GN (green), GY (gray), IV (ivory), OR (orange), PR (purple), RD (red), YL (yellow), TB (TIA blue), TG (TIA green), TN (TIA brown), TO (TIA orange), TP (TIA purple), TR (TIA red), TY (TIA yellow)