

# MDU / SFU

## Product Ordering Guide





# BROADBAND SOLUTIONS OVERVIEW

---

Belden and its broadband connected brands, PPC, Precision OT and Sichert, are worldwide leaders in the design and manufacture of connective technology used in broadband and telecommunications networks. Belden's award-winning fiber optic solutions are utilized globally by operators to provide unparalleled performance to customers around the world, including in support of 5G services. In recent years, Belden has grown its fiber portfolio through research and development, as well as through acquisitions, and Belden continues to build on decades of innovation and to strengthen our partnership with network operators and service providers the world over.

## Table of Contents

<b>Product Overview</b>	<b>4-5</b>
<b>Empty Fiber Enclosures</b>	<b>6</b>
<b>Fiber NID</b>	<b>7-8</b>
<b>Other NIDs</b>	<b>9-11</b>
<b>Slack Storage</b>	<b>12</b>
<b>Patch Only</b>	<b>13-15</b>
<b>Pre-terminated MDU Solutions: Fiber Terminals and Collectors</b>	<b>16</b>
<b>Patch &amp; Splice</b>	<b>17-19</b>
<b>Splice Only</b>	<b>20</b>
<b>Splitter Enclosures</b>	<b>21-25</b>
<b>Fiber Hubs</b>	<b>26-29</b>
<b>MPO - MPO Cables for Density-Optimized Fiber Networks</b>	<b>29</b>
<b>Fiber Markers</b>	<b>29</b>
<b>Pedestal Terminals</b>	<b>30</b>
<b>PPC QuikPass™ Solutions</b>	<b>31-32</b>
<b>Fiber Wall Plates and Accessories</b>	<b>33-37</b>
<b>Accessories</b>	<b>38-42</b>

## Product Overview

**FutureLink®** allows service providers to grow and upgrade as required through a variety of modular and stackable enclosures, splitter modules, connectors/adapters, and fiber cables.

Products are designed for small to large capacity requirements, indoor or outdoor environments, single family homes and neighborhoods, garden style and high-rise buildings or MDU/MTU applications.

Application Guide	Capacity	Empty	Slack	Patch	Splice	Split	Patch & Splice	Patch, Splice, & Split
<b>UCS</b>	Large	●	●	●	●	●	●	●
<b>FITS</b>	Medium			●			●	
<b>SFIT</b>	Medium	●	●	●	●	●	●	●
<b>SNID</b>	Small		●	●	●	●	●	
<b>PAT</b>	Small			●	●		●	●
<b>DTS</b>	Small	●	●	●	●		●	

**UCS — Universal Closure System** is the full-size fiber deployment solution for indoor/outdoor, residential, commercial, and single or multiple family unit applications. Lightweight and easy to install, UCS terminals offer a large range of configuration options for managing patch, splice, split, and slack storage requirements. Stack enclosures for larger capacity installations. Install on a flat surface. Pole mounting and pedestal mounting brackets are also available.

**Materials:** UL 94V-0 (indoor), UL 94-5VA (outdoor) flame-retardant thermoplastic  
**Standards:** Listed UL 1863  
 Designed to meet GR-3123-CORE, GR-3125-CORE & GR-771-CORE  
**NEMA Rating:** NEMA 3R  
**Color:** Light Gray



**FITS — Fiber Interface Terminal System** is a medium sized fiber deployment solution for indoor/outdoor, residential, commercial and single or multiple family units. Its UCS size footprint provides room for many different options for managing slack storage, patching, and splicing. Install on a flat surface. Pedestal mounting brackets are also available.

**Materials:** UL 94V-0 (indoor), UL 94-5VA (outdoor) flame-retardant thermoplastic  
**Standards:** Listed UL 1863  
 Designed to meet GR-3123-CORE, GR-3125-CORE & GR-771-CORE  
**NEMA Rating:** NEMA 3R  
**Color:** Light Gray



**SFIT — Stackable Fiber Interface Terminal** is the medium sized fiber deployment solution for indoor/outdoor, residential, commercial and single or multiple family units. Its compact design and small footprint allows flexibility for installation placement with many different options for managing slack storage, patch, splice, and split requirements. Install on a flat surface or pole mount with optional kit.

**Materials:** UL 94V-0 (indoor), UL 94-5VA (outdoor) flame-retardant thermoplastic  
**Standards:** Listed UL 1863  
 Designed to meet GR-049-CORE, GR-3125-CORE & GR-2898-CORE  
**NEMA Rating:** NEMA 3R  
**Color:** Light Gray



# Product Overview

**PAT — Pedestal Access Terminal** offers a flexible solution for FTTH deployments. Designed to fit in pedestals as small as six inches (nominal diameter), these enclosures can be deployed in both greenfield and brownfield projects. Equipped with up to 12 SC/APC adapters, a splice tray, or both. The terminals make the task of distributing individual drop cables easy.



All PATs include universal mounting bracket (wall, pole or pedestal). Replacement mounting brackets are also available.

- Materials:** UL 94V-0 (indoor), UL 94-5VA (outdoor) flame-retardant thermoplastic
- Standards:** Designed to meet GR-13-CORE & GR-771-CORE
- NEMA Rating:** NEMA 3R
- Color:** Light Gray

**DTS — Drop Terminal System** is a compact NID enclosure designed to protect the transition from the outside plant cable to indoor-rated drop in SFU applications. The terminal's design offers a sleek and unobtrusive profile on the exterior of single-family homes.



Mount on a flat surface with screws or appropriate hardware. Cable channel (stackable) is also available.

- Materials:** UL 94V-0 (indoor), UL 94-5VA (outdoor) flame-retardant thermoplastic
- Standards:** Listed UL 1863  
Designed to meet GR-049-CORE, GR-3123-CORE, GR-3125-CORE & GR-2898-CORE
- NEMA Rating:** NEMA 3R
- Color:** Light Gray

**Fiber Wall Plates** offer a termination point for fiber that runs all the way into the premises. Fiber wall plates come in single or double gang size and feature flexibility of access, mounting options and fiber slack storage.



 
- Materials:** High Impact UL 94V-0 (indoor), UL 94-5VA (outdoor) flame-retardant thermoplastic
- Standards:** Listed UL 1863  
Designed to meet GR-3123-CORE & GR-3125-CORE
- Color:** White

**Accessories** are compatible with most fiber terminals. Some accessories are specific to the type of fiber terminal. See the Accessories section for details.

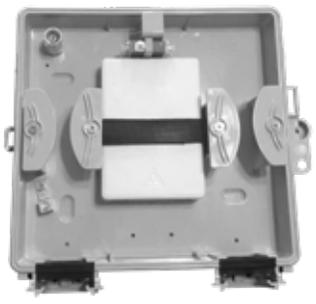
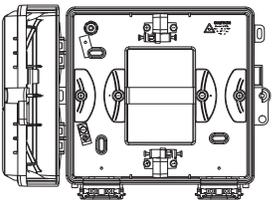
**Density-Optimized Systems** are designed for medium-to-large MDU projects. These solutions reduce installation time and cost using a plug and play configuration throughout the network. The feed cable is spliced at the curb and the remaining connections are based on splitter cassettes and MPO-type cables making the system ideal for projects where ONTs are in each living unit.



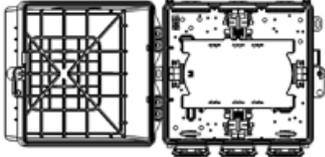
# Empty Fiber Enclosures

Part Number	Description	
DTS-01XC	Empty DTS with one SC simplex adapter frame, rubber grommets on bottom and rear wall (3.8 in W x 7.3 in H x 1.7 in D)	
NID1093-ONT	1-port Patch Only SC-APC Large House Box NID, single tie down ground lug, fiber managers and mounting screws (11.5 in H x 11.5 in W x 5 in D)	
SFIT-FL00NNNN-001	Empty SFIT with U-shape lay-in grommets and pole mount brackets (10 in W x 9 in H x 5 in D)	
HB1094RC74	Empty House Box with 7x4 inch removable rear wall section, U-shape lay-in cable and conduit ports, mounting screws (10.5 in H x 11.5 in W x 5 in D)	
UCS-13138-61CL	Empty UCS with two 1.2-inch Closed Cap upper ports, two 12x 0.45-inch Closed Cap lower ports (14 in W x 14 in H x 8 in D)	
UCS-13138C2C-CL	Empty UCS with two 1.2-inch Closed Cap upper ports, one 12x 0.45-inch Closed Cap, one 2-inch EMT Conduit (SCC-2C) lower port (14 in W x 14 in H x 8 in D)	
UCS-13138G2-CL	Empty UCS with two 1.2-inch Closed Cap upper ports, one 12x 0.45-inch Closed Cap, one Rubber Cone Grommet (UCS-G2) lower port (14 in W x 14 in H x 8 in D)	
UCS-18187-61	Indoor MDU Enclosure with U-shape lay-in grommets (18 in W x 18 in H x 7 in D). Not compatible with other UCS accessories	
SME15AP-BASE	15-inch Plastic Media Enclosure with Rough-in Back Cover (14.4 in W x 15 in H x 3.4 in D) 6 per carton (Order Multiple = 6)	
SME15AP-DOOR	15-inch Vented Plastic Reversible Door and Door Frame, (18.5 in W x 18 in H x 0.6 in D) 6 per carton (Order Multiple = 6)	
SME30AP-BASE	30-inch Plastic Media Enclosure with Rough-in Back Cover (14.4 in W x 30 in H x 3.4 in D) 6 per carton (Order Multiple = 6)	
SME30AP-DOOR	30-inch Vented Plastic Reversible Door and Door Frame (18.5 in W x 33 in H x 0.6 in D) 6 per carton (Order Multiple = 6)	

 
# Fiber NID

Part Number	Description	
NID872-SA	1-port Patch Only SC-APC Small House Box NID, single tie down ground lug and mounting screws (9 in H x 9 in W x 3.5 in D)	
NID872-ACN	1-port Patch & Splice SC-APC Small House Box NID, 4F splice case, single tie down ground lug and mounting screws (9 in H x 9 in W x 3.5 in D)	
NID1093-SA	1-port Patch Only SC-APC Large House Box NID, single tie down ground lug and mounting screws (11.5 in H x 11.5 in W x 5 in D)	
NID1093-ACN	1-port Patch & Splice SC-APC Large House Box NID, 4F splice case, single tie down ground lug and mounting screws (11.5 in H x 11.5 in W x 5 in D)	
DTS-01AC	1-port Patch Only SC-APC, grommets on bottom and rear wall, dual tie down ground block (3.8 in W x 7.3 in H x 1.7 in D)	
DTS-01ACN	1-port Patch & Splice SC-APC, splice holder, grommets on bottom and rear wall, dual tie down ground block (3.8 in W x 7.3 in H x 1.7 in D)	
SUC-02-24-C	2-foot Cable Channel for DTS, 216c captive security screw; cut to length or stackable to extend length (2.2 in W x 24.5 in H x 1.1 in D)	
SFIT-FK01ACN-002	1-port Patch & Splice SC-APC (room for 2 adapters), removable 4F splice case, U-shape lay-in grommets, rear wall grommet, single tie down ground lug, binding post, cable ties with integrated cable tie bases (10 in W x 9 in H x 3 in D)	
SFIT-FK01ACN-004	1-port Patch & Splice SC-APC (room for 4 adapters), removable 4F splice case, U-shape lay-in grommets, rear wall grommet, single tie down ground lug, binding post, cable ties with integrated cable tie bases, upper and lower fiber routers (10 in W x 9 in H x 3 in D)	
SFIT-FK02ACN-002	2-port Patch & Splice SC-APC, removable 4F splice case, U-shape lay-in grommets, rear wall grommet, single tie down ground lug, binding post, cable ties with integrated cable tie bases (10 in W x 9 in H x 3 in D)	
SFIT-FK02ACN-004	2-port Patch & Splice SC-APC (room for 4 adapters), removable 4F splice case, U-shape lay-in grommets, rear wall grommet, single tie down ground lug, binding post, cable ties with integrated cable tie bases, upper and lower fiber routers (10 in W x 9 in H x 3 in D)	
SFIT-FK04ACN-004	4-port Patch & Splice SC-APC, removable 4F splice case, U-shape lay-in grommets; rear wall grommet, single tie down ground lug, binding post, cable ties with integrated cable tie bases, upper and lower fiber routers (10 in W x 9 in H x 3 in D)	

## Fiber NID (cont.)

Part Number	Description	
SFIT-FK01AJN-SPW	1-port Patch & Splice SC-APC (room for 2 adapters), two integrated splice holders, U-shape lay-in grommets, rear wall grommet, single tie down ground lug, dual tie down ground block, binding post, cable ties with integrated cable tie bases (10 in W x 9 in H x 3 in D)	
SFIT-FK01AJN-002 SNID-F602AXNN-CL	1-port Patch & Splice SC-APC (room for 2 adapters), two integrated splice holders, U-shape lay-in grommets, rear wall grommet, single tie down ground lug, binding post, cable ties with integrated cable tie bases. (10 in W x 9 in H x 3 in D). SNID-F602AXNN-CL packaged 6 per carton.	
SNID-F602AXNN-ES	1-port Patch & Splice SC-APC (room for 2 adapters), two integrated splice holders, U-shape lay-in grommets, rear wall grommet, single tie down ground lug, cable ties with integrated cable tie bases and external stud for locating services. (10 in W x 9 in H x 3 in D). Packaged 6 per carton.	
SFIT-FK01AJN-004	1-port Patch & Splice SC-APC (room for 4 adapters), two integrated splice holders, U-shape lay-in grommets, rear wall grommet, single tie down ground lug, binding post, cable ties with integrated cable tie bases, upper and lower fiber routers (10 in W x 9 in H x 3 in D)	
SFIT-FK02AJN-002	2-port Patch & Splice SC-APC, two integrated splice holders, U-shape lay-in grommets, rear wall grommet, single tie down ground lug, binding post, cable ties with integrated cable tie bases (10 in W x 9 in H x 3 in D)	
SFIT-FK02AJN-004	2-port Patch & Splice SC-APC (room for 4 adapters), two integrated splice holders, U-shape lay-in grommets, rear wall grommet, single tie down ground lug, binding post, cable ties with integrated cable tie bases, upper and lower fiber routers (10 in W x 9 in H x 3 in D)	
SFIT-FK03AJN-004	3-port Patch Only SC-APC (empty) for 1x2 Box-type Splitter, U-shape lay-in grommets, rear wall grommet, single tie down ground lug, binding post, cable ties with integrated cable tie bases, upper and lower fiber routers (10 in W x 9 in H x 3 in D)	
SFIT-FK04AJN-004 SNID-F604AXNN-CL	4-port Patch Only SC-APC, U-shape lay-in grommets, rear wall grommet, single tie down ground lug, binding post, cable ties with integrated cable tie bases, upper and lower fiber routers (10 in W x 9 in H x 3 in D). SNID-F604AXNN-CL packaged 6 per carton.	
SFIT-FL02AAN-001	2-port Patch & Splice SC-APC, removable 12F/24F splice tray, U-shape lay-in grommets, single tie down ground lug, compatible with all SFIT Nozzles (10 in W x 9 in H x 5 in D)	

## Other NIDs

Part Number	Description	
PHB872NB	House Box Demarc Empty with Cable/Conduit Grommet and Mounting Screws (9 in H x 9 in W x 3.5 in D)	
PHB872NB-SA	House Box Demarc with Flanged SC Adapter, Cable/Conduit Grommet and Mounting Screws (9 in H x 9 in W x 3.5 in D)	
PHB1093NB	House Box Demarc Empty with Cable/Conduit Grommet and Mounting Screws (11.5 in H x 11.5 in W x 5 in D)	
PHB1093NB-SA	House Box Demarc with Flanged SC Adapter, Cable/Conduit Grommet and Mounting Screws (11.5 in H x 11.5 in W x 5 in D)	
QDRA-6	FlexPON® Spool empty (no fiber) with mounting screw (6.5 in W x 6.5 in H x 1.5 in D)	
XPNXX	1-port FlexPON® Patch Only empty enclosure, no fiber, no spool, single tie down ground lug (8 in W x 10 in H x 4.25 in D)	
XPTXX	2-port FlexPON® Patch & Splice empty enclosure, no fiber, no spool, single tie down ground lug (8 in W x 10 in H x 4.25 in D)	
XPTXX1094	2-port FlexPON® Patch & Splice NID, empty spool, single tie down ground lug (8 in W x 10 in H x 4.25 in D)	
FDJM1DL	Fiber Demarc Junction Manager with hinged partition, single tie down ground lug, slack storage, cable grommets, mounting screws and standard cover (11in W x 12in H x 6.8in D)	
FDJM1SL	Fiber Demarc Junction Manager with Hinged Partition, Single Tie Down Ground Lug, Slack Storage, Cable Grommets, Mounting Screws and Shallow Cover (11in W x 12in H x 5in D)	
FDJM2DL	Fiber Demarc Junction Manager with Hinged Partition, Single Tie Down Ground Lug, Slack Storage, Splice Block, Mounting Screws and Standard Cover (11in W x 12in H x 6.8in D)	
FDJM2SL	Fiber Demarc Junction Manager with Hinged Partition, Single Tie Down Ground Lug, Slack Storage, Splice Block, Mounting Screws and Shallow Cover (11in W x 12in H x 5in D)	
FDJM3DL	Fiber Demarc Junction Manager, single tie down ground lug, slack storage, cable grommets, mounting screws and standard cover (11in W x 12in H x 6.8in D)	
		

## Other NIDs (cont.)

Part Number	Description
XPNX-392RIWb5s5050 BPNX-321RIWb5s5050	1-port FlexPON® Patch Only NID, single tie down ground lug, White Riser 3mm 900u A2 SCA to SCA 50ft (8 in W x 10 in H x 4.25 in D).
XPNX-392RIWb5s5100 BPNX-321RIWb5s5100	1-port FlexPON® Patch Only NID, single tie down ground lug, White Riser 3mm 900u A2 SCA to SCA 100ft (8 in W x 10 in H x 4.25 in D).
XPNX-392RIWb5s5150 BPNX-321RIWb5s5150	1-port FlexPON® Patch Only NID, single tie down ground lug, White Riser 3mm 900u A2 SCA to SCA 150ft (8 in W x 10 in H x 4.25 in D).
XPNX-392RIWb5s5190 BPNX-321RIWb5s5190	1-port FlexPON® Patch Only NID, single tie down ground lug, White Riser 3mm 900u A2 SCA to SCA 190ft (8 in W x 10 in H x 4.25 in D).
XPNX-392PBBb5s5050 BPNX-321PBBb5s5050	1-port FlexPON® Patch Only NID, single tie down ground lug, Black PBT 3mm 900u A2 SCA to SCA 50ft (8 in W x 10 in H x 4.25 in D).
XPNX-392PBBb5s5100 BPNX-321PBBb5s5100	1-port FlexPON® Patch Only NID, single tie down ground lug, Black PBT 3mm 900u A2 SCA to SCA 100ft (8 in W x 10 in H x 4.25 in D).
XPNX-392PBBb5s5150 BPNX-321PBBb5s5150	1-port FlexPON® Patch Only NID, single tie down ground lug, Black PBT 3mm 900u A2 SCA to SCA 150ft (8 in W x 10 in H x 4.25 in D).
XPNX-392PBBb5s5190 BPNX-321PBBb5s5190	1-port FlexPON® Patch Only NID, single tie down ground lug, Black PBT 3mm 900u A2 SCA to SCA 190ft (8 in W x 10 in H x 4.25 in D).
XPNX-392PBBb3s3050 BPNX-321PBBb3s3050	1-port FlexPON® Patch Only NID, single tie down ground lug, Black PBT 3mm 900u A2 SCU to SCU 50ft (8 in W x 10 in H x 4.25 in D).
XPNX-392PBBb3s3100 BPNX-321PBBb3s3100	1-port FlexPON® Patch Only NID, single tie down ground lug, Black PBT 3mm 900u A2 SCU to SCU 100ft (8 in W x 10 in H x 4.25 in D).
XPNX-392PBBb3s3150 BPNX-321PBBb3s3150	1-port FlexPON® Patch Only NID, single tie down ground lug, Black PBT 3mm 900u A2 SCU to SCU 150ft (8 in W x 10 in H x 4.25 in D).
XPNX-392PBBb3s3190 BPNX-321PBBb3s3190	1-port FlexPON® Patch Only NID, single tie down ground lug, Black PBT 3mm 900u A2 SCU to SCU 190ft (8 in W x 10 in H x 4.25 in D).

BABA compliant options available



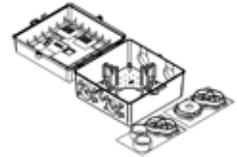
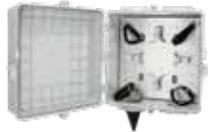
## Other NIDs (cont.)

Part Number	Description
XPTX-392PBBb5s5050 BPTX-321PBBb5s5050	2-port FlexPON® Patch & Splice NID, single tie down ground lug, Black PBT 3mm 900u A2 SCA to SCA 50ft (8 in W x 10 in H x 4.25 in D).
XPTX-392PBBb5s5100 BPTX-321PBBb5s5100	2-port FlexPON® Patch & Splice NID, single tie down ground lug, Black PBT 3mm 900u A2 SCA to SCA 100ft (8 in W x 10 in H x 4.25 in D).
XPTX-392PBBb5s5150 BPTX-321PBBb5s5150	2-port FlexPON® Patch & Splice NID, single tie down ground lug, Black PBT 3mm 900u A2 SCA to SCA 150ft (8 in W x 10 in H x 4.25 in D).
XPTX-392PBBb5s5190 BPTX-321PBBb5s5190	2-port FlexPON® Patch & Splice NID, single tie down ground lug, Black PBT 3mm 900u A2 SCA to SCA 190ft (8 in W x 10 in H x 4.25 in D).

 
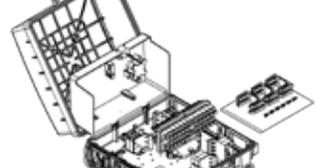
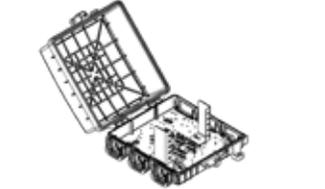
• **BABA compliant options available**



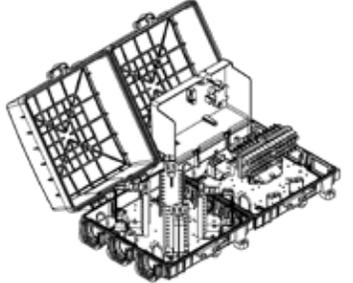
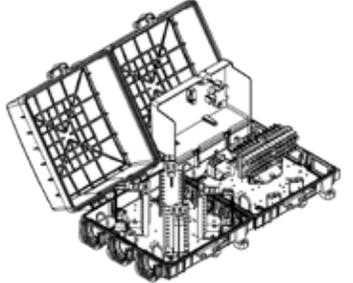
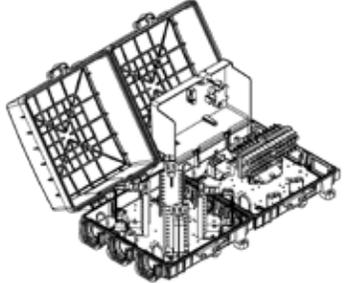
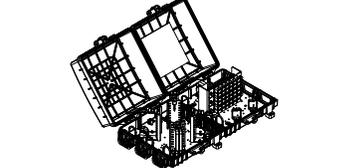
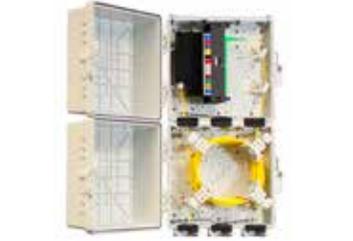
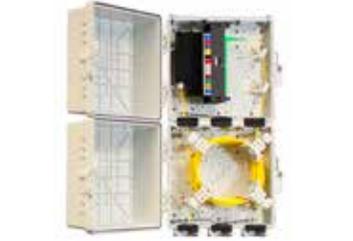
# Slack Storage

Part Number	Description	
CON-2221-85	Slack Storage Surface Mount Fiber Wall Plate, 6port Double Wide, White (6.7 in W x 5.5 in H x 1.5 in D).	
SNID-F300XXN-CL	SFIT Slack Storage with flat rubber grommets; 3 upper ports; 3 lower ports; compatible with all SFIT Nozzles (10 in W x 6 in H x 3 in D).	
SNID-F600XXN-CL	SFIT Slack Storage with flat rubber grommets; 3 upper ports; 3 lower ports; compatible with all SFIT Nozzles (10 in W x 9 in H x 3 in D).	
SFIT-FL00BNN	SFIT Slack Storage with flat rubber grommets, double-stack rubber grommets, tall fiber routers, single tie down ground lug, cable ties and bases (10 in W x 9 in H x 5 in D). Can add onto existing SFIT enclosures.	
SFIT-FL00BNX-001	SFIT Slack Storage with flat rubber grommets, double-stack rubber grommets, tall fiber routers, single tie down ground lug, cable ties and bases, removable rear conduit port, upper and lower 1.25-inch conduit nozzles (10 in W x 9 in H x 5 in D). Can add onto existing SFIT enclosures.	
UCS-FS00BNX-001	UCS Slack Storage for conduit with four fiber routers, one input cable strain relief bracket, two 1.2-inch Closed Cap ports, two UCS PVC Coupler Kits (SCC-UUF) for stacking two UCS enclosures together. 4-5/8-inch conduit access hole in the back wall of the enclosure (14 in W x 14 in H x 8 in D).	
UCS-FS00XXNN-JB	UCS Slack Storage with four fiber spools and four Velcro straps, three 1.2-inch Closed Cap ports and one Rubber Cone Grommet port (14 in W x 14 in H x 8 in D).	
UCS-18187-61SS	Slack Storage Box (18 in W x 18 in H x 7 in D) with two slack storage arms, metal T-Bracket for maintenance hole ladder rack brackets, four flat rubber grommets.	

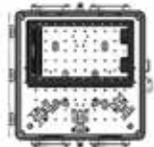
 
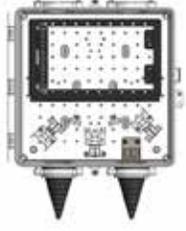
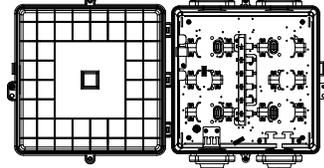
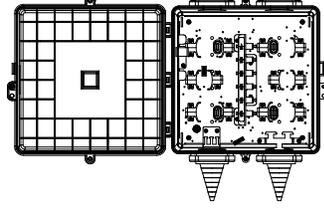
## Patch Only

Part Number	Description	
SNID-F308AXNN (APC)	4-port Patch Only SC (expandable to 16), U-shape lay-in grommets, single tie down ground lug, dual tie down ground block, cable ties and bases. 3 upper ports; 3 lower ports; compatible with all SFIT Nozzles (10 in W x 6 in H x 5 in D).	
SNID-F616AXNN (APC)	8-port Patch Only SC (expandable to 24), U-shape lay-in grommets, single tie down ground lug, dual tie down ground block, cable ties and bases. 3 upper ports; 3 lower ports; compatible with all SFIT Nozzles (10 in W x 9 in H x 5 in D).	
SFIT-FL12AXNN (APC) SNID-F612UXNN-CL (UPC)	12-port Patch Only SC (expandable to 24), U-shape lay-in grommets, single tie down ground lug, dual tie down ground block, cable ties and bases. 3 upper ports; 3 lower ports; compatible with all SFIT Nozzles (10 in W x 9 in H x 5 in D).	
SFIT-FL12AXNN-LC (APC) SFIT-FL12UXNN-LC (UPC)	12-port Patch Only LC (expandable to 24), U-shape lay-in grommets, single tie down ground lug, dual tie down ground block, cable ties and bases. 3 upper ports; 3 lower ports; compatible with all SFIT Nozzles (10 in W x 9 in H x 5 in D).	
SFIT-FL16AXNN (APC)	16-port Patch Only SC (expandable to 24), U-shape lay-in grommets, double-stack rubber grommets, single tie down ground lug, cable ties and bases. Capable of holding 1x4 or 1x8 or 1x16 Mini Splitters (10 in W x 9 in H x 5 in D). Can add onto existing SFIT enclosures.	
SFIT-FL24AXNN (APC) SFIT-FL24UXNN (UPC)	24-port Patch Only SC, U-shape lay-in grommets, three double-stack rubber grommets, single tie down ground lug, dual tie down ground block, cable ties and bases (10 in W x 9 in H x 5 in D). Can add onto existing SFIT enclosures.	
SFIT-FL32AXNN (APC)	32-port Patch Only SC, U-shape lay-in grommets, double-stack rubber grommets, single tie down ground lug, cable ties and bases. Capable of holding 1x16 or 1x32 Mini Splitters (10 in W x 9 in H x 5 in D). Can add onto existing SFIT enclosures.	
SFIT-FL00CNN-LGX	Patch Only (empty) Enclosure for 1-3 LGX modules, U-shape lay-in grommets and double-stack rubber grommets (10 in W x 9 in H x 5 in D). Can add onto existing SFIT enclosures.	
SFIT-FL12AXNN-01 (APC) SFIT-FL12AXNN-02 (APC) SFIT-FL36AXNN-03 (APC)	12-port / 24-port / 36-port Patch Only SC with 12port LGX Bulkhead Panels, U-shape lay-in grommets, double-stack rubber grommets, metal cable tie down brackets (10 in W x 9 in H x 5 in D). Can add onto existing SFIT enclosures.	
SFIT-FH12BXNN	12port Patch Only SC (expandable to 24), Black SC Simplex Adapters, U-shape lay-in grommets, tall slack storage, single tie down ground lug, cable ties and bases, removable rear conduit port (10 in W x 15 in H x 5 in D).	

## Patch Only (cont.)

Part Number	Description	
FITS-02APXNN-CL (APC) FITS-04APXNN-CL (APC) FITS-06APXNN-CL (APC)	2-port / 4-port / 6-port Patch Only SC, dual round drop clamp inputs, dual tie down ground block, slack storage, separation wall and nozzle for drop cables (13 in W x 13.3 in H x 4.3 in D).	
FITS-12APXNN-CL (APC) FITS-12UPXNN-CL (UPC) FITS-24APXNN-CL (APC) FITS-24UPXNN-CL (UPC)	12-port / 24-port Patch Only SC, dual round drop clamp inputs, dual tie down ground block, slack storage, separation wall and nozzle for drop cables (13 in W x 13.3 in H x 4.3 in D).	
SFIT-FT16AXNN (APC)	16-port Patch Only SC (expandable to 24), tall slack storage, U-shape lay-in grommets, single tie down ground lug, cable ties and bases. Capable of holding 1x4 or 1x8 or 1x16 Mini Splitters (10 in W x 18 in H x 5 in D).	
SFIT-FT24AXNN (APC) SFIT-FT24UXNN (UPC)	24-port Patch Only SC, tall slack storage, U-shape lay-in grommets, single tie down ground lug, cable ties and bases (10 in W x 18 in H x 5 in D).	
SFIT-FT32AXNN (APC)	32-port Patch Only SC, tall slack storage, U-shape lay-in grommets, single tie down ground lug, cable ties and bases. Capable of holding 1x16 or 1x32 Mini Splitters (10 in W x 18 in H x 5 in D).	
SFIT-FT36AXNN-03 (APC)	36-port Patch Only SC, tall slack storage, U-shape lay-in grommets, single tie down ground lug, cable ties and bases (10 in W x 18 in H x 5 in D).	
SFIT-FL00CNN-002	Patch Only Empty Enclosure for 1-3 SCM-12xM2N MPO fanout cassette modules, U-shape lay-in grommets and double-stack rubber grommets (10 in W x 9 in H x 5 in D). Can add onto existing SFIT enclosures.	
SFIT-FT00CNN-001	Patch Only Empty Enclosure for 1-3 SCM-12xM2N MPO fanout modules, U-shape lay-in grommets, tall slack storage, 24-port F1 nozzle and 24-port F2 nozzle (10 in W x 18 in H x 5 in D).	
SFIT-FT00CNN-002	Patch Only Empty Enclosure for 1-3 SCM-12xM2N MPO fanout modules, U-shape lay-in grommets, tall slack storage (10 in W x 18 in H x 5 in D).	

## Patch Only (cont.)

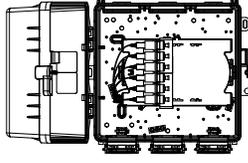
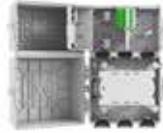
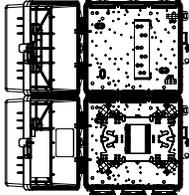
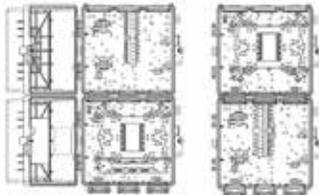
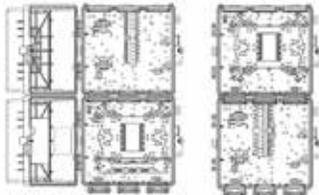
Part Number	Description	
SCM-12ACM2N (APC) SCM-12UCM2N (UPC)	12-port MPO to 12 SC Fanout Module, single 12F MPO male pinned connector (1-3 per SFIT MPO Enclosure).	
UCS-FS00CNN-002	Patch Only Empty Enclosure for 1-10 SCM-12xM2N MPO fanout modules, slack storage, two 1.2-inch Closed Cap ports, two Rubber Cone Grommet ports (14 in W x 14 in H x 8 in D).	
UCS-FD00CNN-002	Patch Only Empty Enclosure for 1-10 SCM-12xM2N MPO fanout modules, tall slack storage, two 1.2-inch Closed Cap ports, two Rubber Cone Grommet ports (14 in W x 30 in H x 8 in D)	
UCS-FS00CNN-003	Patch Only Empty Enclosure for 1-9 LGX modules, slack storage, two 1.2-inch Closed Cap ports, two Rubber Cone Grommet ports (14 in W x 14 in H x 8 in D).	
UCS-FD00CNN-003	Patch Only Empty Enclosure for 1-9 LGX modules, tall slack storage, two 1.2-inch Closed Cap ports, two Rubber Cone Grommet ports (14 in W x 30 in H x 8 in D).	
UCS-FS72AXNN-JB (APC) UCS-FS72UXNN (UPC)	24-port Patch Only SC (expandable to 72), three 1.2-inch Closed Cap ports, one Rubber Cone Grommet port, one 12/24F splice tray bracket (14 in W x 14 in H x 8 in D). SFST-24SFT Splice Tray sold separately.	
UCS-FS72AXNN-48 (APC) UCS-FS72UXNN-48 (UPC)	48-port Patch Only SC (expandable to 72), three 1.2-inch Closed Cap ports, one Rubber Cone Grommet port, one 12/24F splice tray bracket (14 in W x 14 in H x 8 in D). SFST-24SFT Splice Tray sold separately.	
UCS-FS72AXNN-72 (APC) UCS-FS72UXNN-72 (UPC)	72-port Patch Only SC, three 1.2-inch Closed Cap ports, one Rubber Cone Grommet port, one 12/24F splice tray bracket (14 in W x 14 in H x 8 in D). SFST-24SFT Splice Tray sold separately.	

## Pre-terminated MDU Solutions: Fiber Terminals, Collectors and Hubs

Part Number	Description
ADTSA-1SAFM100	Terminal System Assembly (TSA) 12-port SC-APC to 100 ft Plenum non-pinned MPO
ADTSA-1SAFM250	Terminal System Assembly (TSA) 12-port SC-APC to 250 ft Plenum non-pinned MPO
ADTSA-1SAFM500	Terminal System Assembly (TSA) 12-port SC-APC to 500 ft Plenum non-pinned MPO
ADTSA-1SAFM800	Terminal System Assembly (TSA) 12-port SC-APC to 800 ft Plenum non-pinned MPO
ADTSA-1SAFM1000	Terminal System Assembly (TSA) 12-port SC-APC to 1000 ft Plenum non-pinned MPO
ADTSB-1SAFM100	Terminal System Assembly (TSA) 24-port SC-APC to 100 ft Plenum non-pinned MPO
ADTSB-1SAFM250	Terminal System Assembly (TSA) 24-port SC-APC to 250 ft Plenum non-pinned MPO
ADTSB-1SAFM500	Terminal System Assembly (TSA) 24-port SC-APC to 500 ft Plenum non-pinned MPO
ADTSB-1SAFM800	Terminal System Assembly (TSA) 24-port SC-APC to 800 ft Plenum non-pinned MPO
ADTSB-1SAFM1000	Terminal System Assembly (TSA) 24-port SC-APC to 1000 ft Plenum non-pinned MPO
ACTP6-1MMNC100	Collector Terminal 12port SC-APC 072F Riser 100 ft Stub
ACTP6-1MMNC250	Collector Terminal 12port SC-APC 072F Riser 250 ft Stub
ACTP6-1MMNC500	Collector Terminal 12port SC-APC 072F Riser 500 ft Stub
ACTP12-1MMNC100	Collector Terminal 24port SC-APC 144F Riser 100 ft Stub
ACTP12-1MMNC250	Collector Terminal 24port SC-APC 144F Riser 250 ft Stub
ACTP12-1MMNC500	Collector Terminal 24port SC-APC 144F Riser 500 ft Stub
AMCP6-1MMNC100	Assembly, Collector 072F Riser 100 ft Stub
AMCP6-1MMNC250	Assembly, Collector 072F Riser 250 ft Stub
AMCP6-1MMNC500	Assembly, Collector 072F Riser 500 ft Stub
AMCP12-1MMNC100	Assembly, Collector 144F Riser 100 ft Stub
AMCP12-1MMNC250	Assembly, Collector 144F Riser 250 ft Stub
AMCP12-1MMNC500	Assembly, Collector 144F Riser 500 ft Stub



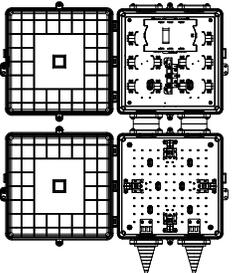
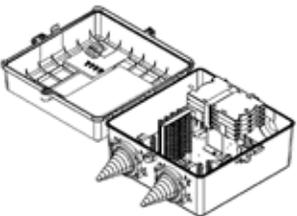
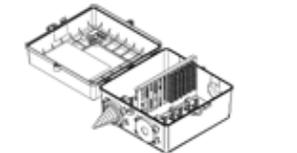
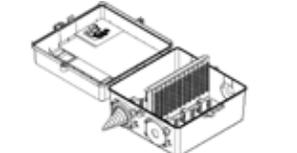
# Patch & Splice

Part Number	Description	
FITS-12APSNN-CL (APC) FITS-12UPSNN-CL (UPC) FITS-24APSNN-CL (APC) FITS-24UPSNN-CL (UPC)	12-port / 24-port Patch and Splice SC, one 12/24F splice tray, dual round drop clamp inputs, dual tie down ground block, slack storage, separation wall and nozzle for drop cables (13 in W x 13.3 in H x 4.3 in D). No 12F breakout cables.	
FITS-12APS4NB-CL (APC) FITS-12UPS4NB-CL (UPC) FITS-24APS4NB-CL (APC) FITS-24UPS4NB-CL (UPC)	12-port / 24-port Patch and Splice SC, one 12/24F splice tray, one or two 12F breakout cables, dual round drop clamp inputs, dual tie down ground block, slack storage, separation wall and nozzle for drop cables (13 in W x 13.3 in H x 4.3 in D).	
SFIT-FL12AANBO	12-port Patch and Splice SC-APC, 12F SC-APC breakout cable, 12/24F splice tray, U-shape lay-in grommets, slack storage, single tie down ground lug, dual tie down ground block, cable ties and bases (10 in W x 9 in H x 5 in D).	
SFIT-FH12AANBM (APC) SFIT-FH12AANNM (no 12F cable) SFIT-FH12UANBM (UPC) SFIT-FH12UANNM (no 12F cable)	12-port Patch and Splice SC (expandable to 24), one 12/24F splice tray, one 12F SC breakout cable, U-shape lay-in grommets, tall slack storage, single tie down ground lug, cable ties and bases (10 in W x 15 in H x 5 in D).	
SFIT-FH24AANBONNNN (APC) SFIT-FH24AANNONNNN (no cables) SFIT-FH24UANBONNNN (UPC) SFIT-FH24UANNONNNN (no cables)	24-port Patch and Splice SC, one 12/24F splice tray, two 12F SC breakout cables, U-shape lay-in grommets, tall slack storage, single tie down ground lug, cable ties and bases (10 in W x 15 in H x 5 in D).	
SFIT-FT00CNN-LGX	Patch and Splice (empty) Enclosure for 1-3 LGX modules, two 12/24F splice trays, medium slack storage, U-shape lay-in grommets (10 in W x 18 in H x 5 in D).	
SFIT-FT12AANBM-008 (APC) SFIT-FT12UANBM-008 (UPC)	12-port Patch and Splice SC (expandable to 24), bulkhead in the upper box, two 12/24F splice trays in the lower box, one set of 12F color coded 900u pigtails, U-shape lay-in grommets, tall slack storage, single tie down ground lug, cable ties and bases (10 in W x 18 in H x 5 in D).	
SFIT-FT12AANBM-118 (APC) SFIT-FT12UANBM-118 (UPC)	12-port Splice and Patch SC (expandable to 24), bulkhead in the lower box, two 12/24F splice trays in the upper box, one set of 12F color coded 900u pigtails, U-shape lay-in grommets, tall slack storage, single tie down ground lug, cable ties and bases (10 in W x 18 in H x 5 in D).	

## Patch & Splice (cont.)

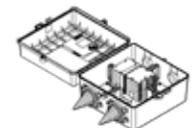
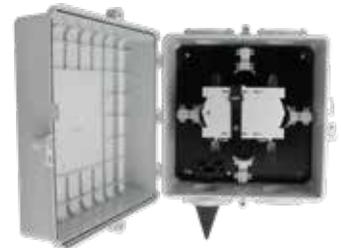
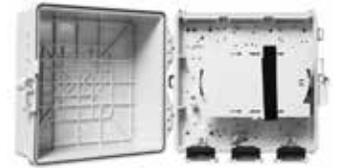
Part Number	Description	
SFIT-FT12AANBO (APC) SFIT-FT12AANNO (no cables) SFIT-FT12UANBO (UPC) SFIT-FT12UANNO (no cables)	12-port Patch and Splice SC (expandable to 24), one 12/24F splice tray, one 12F SC breakout cable, U-shape lay-in grommets, tall slack storage, single tie down ground lug, cable ties and bases (10 in W x 18 in H x 5 in D).	
SFIT-FT16AANNO (APC)	16-port Patch and Splice SC (expandable to 24), two 12/24F splice trays, medium slack storage, U-shape lay-in grommets, single tie down ground lug, cable ties and bases (10 in W x 18 in H x 5 in D).	
SFIT-FT24AANBO (APC) SFIT-FT24AANNO (no cables) SFIT-FT24UANBO (UPC) SFIT-FT24UANNO (no cables)	24-port Patch and Splice SC, one 12/24F splice tray, two 12F SC breakout cables, U-shape lay-in grommets, tall slack storage, single tie down ground lug, cable ties and bases (10 in W x 18 in H x 5 in D).	
SFIT-FT32AANNO (APC)	32-port Patch and Splice SC, two 12/24F splice trays, medium slack storage, U-shape lay-in grommets, single tie down ground lug, cable ties and bases (10 in W x 18 in H x 5 in D).	
SFIT-FT12AANR-001 (APC)	12-port Patch and Splice SC for Flat Ribbon, one 12F SC ribbon breakout cable, tall slack storage, 2-port F1 nozzle, 24-port 8.5mm nozzle, single tie down ground lug, cable ties and bases (10 in W x 18 in H x 5 in D).	
SFIT-FT24AANR-001 (APC)	24-port Patch and Splice SC for Ribbon, two 12F SC ribbon breakout cables, tall slack storage, 2-port F1 nozzle, 24-port 8.5mm nozzle, single tie down ground lug, cable ties and bases (10 in W x 18 in H x 5 in D).	
SFIT-FT12AANR-002 (APC)	12-port Patch and Splice SC for Flat Ribbon, one 12F SC ribbon breakout cable, U-shape lay-in grommets, tall slack storage, single tie down ground lug, cable ties and bases (10 in W x 18 in H x 5 in D).	
SFIT-FT24AANR-002 (APC)	24-port Patch and Splice SC for Flat Ribbon, two 12F SC ribbon breakout cables, U-shape lay-in grommets, tall slack storage, single tie down ground lug, cable ties and bases (10 in W x 18 in H x 5 in D).	

## Patch & Splice (cont.)

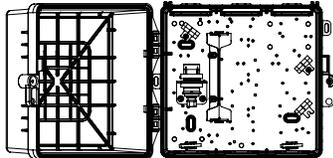
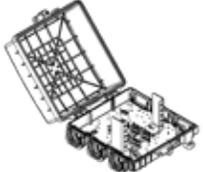
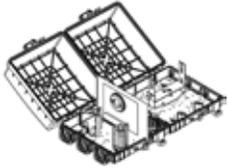
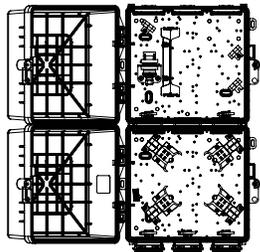
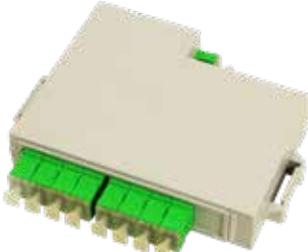
Part Number	Description	
UCS-FD12AS4N (12 APC) UCS-FD24AS4N (24 APC) UCS-FD36AS4N (36 APC) UCS-FD48AS4N (48 APC)	12-port / 24-port / 36-port / 48-port Patch and Splice SC, one, two, three or four 12/24F splice trays and 12F sets of 900u color-coded pigtails, slack storage, two 1.2-inch Closed Cap ports and two cone grommet ports, two extra 2.5-inch PVC Couplers, mounting hardware (14 in W x 30 in H x 8 in D).	
UCS-FD12AS4N-CL (12 APC) UCS-FD12US4N-CL (12 UPC) UCS-FD24AS4N-CL (24 APC) UCS-FD24US4N-CL (24 UPC) UCS-FD36AS4N-CL (36 APC) UCS-FD36US4N-CL (36 UPC)	12-port / 24-port / 36-port Patch and Splice SC, one, two, or three 12/24F splice trays and 12F SC breakout cables, slack storage, three 1.2-inch Closed Cap ports and one 1-inch open port. 4-5/8-inch conduit access hole in the back wall of the lower enclosure (14 in W x 30 in H x 8 in D).	
UCS-FD12AXNN-CL (APC) **** PATCH ONLY **** UCS-FD12UXNN-CL (UPC)	12-port Patch Only SC (expandable to 36), slack storage, three 1.2-inch Closed Cap ports and one 1-inch open port. 4-5/8-inch conduit access hole in the back wall of the lower enclosure (14 in W x 30 in H x 8 in D).	
UCS-FS48AS4N (APC) UCS-FS48ASNN-001 (no cables) UCS-FS48US4N (UPC) UCS-FS48USNN-001 (no cables)	48-port Patch and Splice SC, four 12/24F splice trays, four sets of 12F 1-meter color-coded 900u pigtails, slack storage, two 1.2-inch Closed Cap ports and two Rubber Cone Grommet ports (14 in W x 14 in H x 8 in D).	
UCS-FS72ASNN-001 (APC) UCS-FS72USNN-001 (UPC)	72-port Patch and Splice SC, six 12/24F splice trays, slack storage, two 1.2-inch Closed Cap ports and two Rubber Cone Grommet ports (14 in W x 14 in H x 8 in D).	
UCS-FS72AXNNB-CL (APC)	72-port Patch and Splice SC, one 72F indoor/outdoor 50ft cable stub, slack storage, three 1.2-inch Closed Cap ports and one Rubber Cone Grommet port (14 in W x 14 in H x 8 in D).	
UCS-FS144AXNNB-CL (APC)	144-port Patch and Splice SC, two 72F indoor/outdoor 50ft cable stubs, slack storage, three 1.2-inch Closed Cap ports and one Rubber Cone Grommet port (14 in W x 14 in H x 8 in D).	

# Splice Only

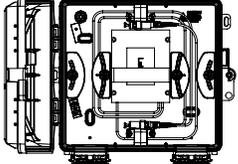
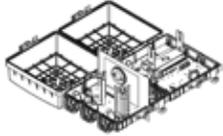
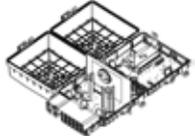
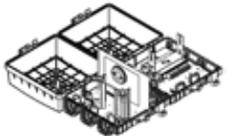
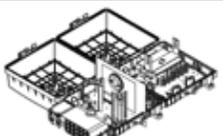
Part Number	Description
SNID-F300NSNN	Splice Only with one 12/24F splice tray (room for 2), U-shape lay-in grommets, short slack storage, two single tie down ground lugs, dual tie down ground block, cable ties and bases. 3 upper ports; 3 lower ports; compatible with all SFIT Nozzles (10 in W x 6 in H x 5 in D).
SNID-F600NSNN	Splice Only with one 12/24F splice tray (room for 3), U-shape lay-in grommets, short slack storage, two single tie down ground lugs, one dual tie down ground block, cable ties and bases, 3 upper ports; 3 lower ports; compatible with all SFIT Nozzles (10 in W x 9 in H x 5 in D) SNID-F600NSNN packaged 4 per carton.
SNID-F600NSNN-02	Splice Only with two 12/24F splice trays (room for 3), U-shape lay-in grommets, short slack storage, two single tie down ground lugs, one dual tie down ground block, metal cable tie down brackets, 3 upper ports; 3 lower ports; compatible with all SFIT Nozzles (10 in W x 9 in H x 5 in D) SNID-F600NSNN packaged 4 per carton.
SFIT-FL00NSNN	Splice Only with one 12/24F splice tray (room for 2), U-shape lay-in grommets, three double-stack rubber grommets, medium slack storage, two single tie down ground lugs, one dual tie down ground block, cable ties and bases (10 in W x 9 in H x 5 in D). Can add onto existing SFIT enclosures.
SFIT-FL01AJNNNNNNN	Splice Only with one 12/24F splice tray, tall slack storage, U-shape lay-in grommets, cable ties and bases, pole mount brackets (10 in W x 9 in H x 5 in D).
UCS-FS72XSNN-JB	Splice Only with one 12/24F splice tray (room for 6), slack storage, three 1.2-inch Closed Cap ports and one Rubber Cone Grommet port (14 in W x 14 in H x 8 in D).
UCS-24XSNN-CL	Splice Only with two 12/24F splice trays (room for 6), slack storage, three 1.2-inch Closed Cap ports and one Rubber Cone Grommet port (14 in W x 14 in H x 8 in D).
UCS-36XSNN-CL	Splice Only with three 12/24F splice trays (room for 6), slack storage, three 1.2-inch Closed Cap ports and one Rubber Cone Grommet port (14 in W x 14 in H x 8 in D).
UCS-72XSNN-CL	Splice Only with six 12/24F splice trays, slack storage, two 1.2-inch Closed Cap ports and two Rubber Cone Grommet ports (14 in W x 14 in H x 8 in D).



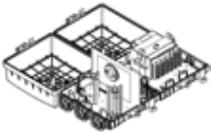
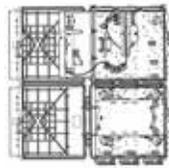
# Splitter Enclosures

Part Number	Description	
SFIT-FL00CNN-001	Splitter Enclosure for 1-3 splitter modules, U-shape lay-in grommets and double-stack rubber grommets (10 in W x 9 in H x 5 in D). Can add onto existing SFIT enclosures.	
SFIT-FL00CNN-003	Splitter Enclosure with HFOC SC-APC Input and short SC-APC jumper for 1 or 2 small splitter modules, U-shape lay-in grommets (10 in W x 9 in H x 5 in D).	
SFIT-FL00CNN-LGX	Splitter Enclosure for 1-3 LGX modules, U-shape lay-in grommets and double-stack rubber grommets (10 in W x 9 in H x 5 in D). Can add onto existing SFIT enclosures.	
SFIT-FT00CNN	Splitter Enclosure for 1-3 splitter modules, tall slack storage, U-shape lay-in grommets, cable ties and bases (10 in W x 18 in H x 5 in D).	
SFIT-FT00CNN-003	Splitter Enclosure with HFOC SC-APC Input and short SC-APC jumper for 1 or 2 small splitter modules, tall slack storage, U-shape lay-in grommets, cable ties and bases (10 in W x 18 in H x 5 in D).	
SFIT-FT00CNN-005	Patch and Splice Splitter Enclosure for 1-3 splitter modules, one 12/24F splice tray (room for 2), medium slack storage, 2-port F1 nozzle, cable ties and bases (10 in W x 18 in H x 5 in D).	
SFIT-FT00CNN-LGX	Patch and Splice Splitter Enclosure for 1-3 LGX modules, two 12/24F splice trays, medium slack storage, U-shape lay-in grommets (10 in W x 18 in H x 5 in D).	
SFSM-C1102AA-S	Splitter Module, 1x2 SC-APC to SC-APC	
SFSM-C1102AU-S	Splitter Module, 1x2 SC-APC to SC-UPC	
SFSM-C1102UA-S	Splitter Module, 1x2 SC-UPC to SC-APC	
SFSM-C1104AA-S	Splitter Module, 1x4 SC-APC to SC-APC	
SFSM-C1104AU-S	Splitter Module, 1x4 SC-APC to SC-UPC	
SFSM-C1104UA-S	Splitter Module, 1x4 SC-UPC to SC-APC	
SFSM-C1108AA-S	Splitter Module, 1x8 SC-APC to SC-APC	
SFSM-C1108AU-S	Splitter Module, 1x8 SC-APC to SC-UPC	
SFSM-C1108UA-S	Splitter Module, 1x8 SC-UPC to SC-APC	

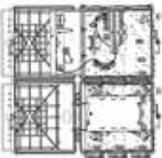
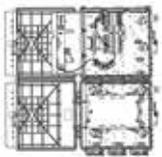
## Splitter Enclosures (cont.)

Part Number	Description	
SF5M-C1116AA-S	Splitter Module, 1x16 SC-APC to SC-APC	
SF5M-C1132AA-S	Splitter Module, 1x32 SC-APC to SC-APC	
SFFO-C04AA-1	Splice Module, 4port Fanout, 4 SC-APC Pigtails (2 per enclosure).	
SFFO-C08AA-1	Splice Module, 8port Fanout, 8 SC-APC Pigtails (2 per enclosure).	
SFIT-FK03AJN-1X2	3-port Patch Only SC-APC with 1x2 Box-type Splitter, U-shape lay-in grommets, rear wall grommet, single tie down ground lug, binding post, cable ties with integrated cable tie bases, upper and lower fiber routers (10 in W x 9 in H x 3 in D)	
SFIT-FT04CNN	4-port Splitter Enclosure, one 1x4 SC-APC splitter module (room for 3), tall slack storage, U-shape lay-in grommets, single tie down ground lug, cable ties and bases (10 in W x 18 in H x 5 in D).	
SFIT-FT04CNN-001	4-port Splitter Enclosure, one 1x4 SC-APC splitter module (room for 3), tall slack storage, single tie down ground lug, 2-port F1 nozzle; 24- port 10mm F2 nozzle, cable ties and bases (10 in W x 18 in H x 5 in D).	
SFIT-FT08CNN	8-port Splitter Enclosure, one 1x8 SC-APC splitter module (room for 3), tall slack storage, U-shape lay-in grommets, single tie down ground lug, cable ties and bases (10 in W x 18 in H x 5 in D).	
SFIT-FT08CNN-001	8-port Splitter Enclosure, one 1x8 SC-APC splitter module (room for 3), tall slack storage, single tie down ground lug, 2-port F1 nozzle; 24- port 10mm F2 nozzle, cable ties and bases (10 in W x 18 in H x 5 in D).	
SFIT-FT16CNN	16-port Splitter Enclosure, one 1x16 SC-APC splitter module (room for 2), tall slack storage, U-shape lay-in grommets, single tie down ground lug, cable ties and bases (10 in W x 18 in H x 5 in D).	
SFIT-FT16CNN-001	16-port Splitter Enclosure, one 1x16 SC-APC splitter module (room for 2), tall slack storage, single tie down ground lug, 2-port F1 nozzle; 24- port 10mm F2 nozzle, cable ties and bases (10 in W x 18 in H x 5 in D).	

## Splitter Enclosures (cont.)

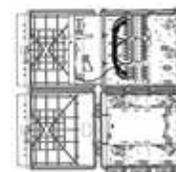
Part Number	Description	
SFIT-FT32CNN	32-port Splitter Enclosure, one 1x32 SC-APC splitter module, tall slack storage, U-shape lay-in grommets, single tie down ground lug, cable ties and bases (10 in W x 18 in H x 5 in D).	
SFIT-FT32CNN-001	32-port Splitter Enclosure, one 1x32 SC-APC splitter module, tall slack storage, single tie down ground lug, 2-port F1 nozzle; 24-port 10mm F2 nozzle, cable ties and bases (10 in W x 18 in H x 5 in D).	
SNID-F604ANAN9N-CL	4-port SNID Legacy Splitter Enclosure, 1x4 pre-terminated SC-APC (10 in W x 9 in H x 3 in D).	
SNID-F608ANBN9N-CL	8-port SNID Legacy Splitter Enclosure, 1x8 pre-terminated SC-APC (10 in W x 9 in H x 3 in D).	
SNID-F616ANQN9N-CL	16-port SNID Legacy Splitter Enclosure, 1x2 pre-terminated SC-APC into two 1x8 pre-terminated SC-APC (10 in W x 9 in H x 3 in D).	
SNID-F616ANCN9N-CL	16-port SNID Legacy Splitter Enclosure, 1x16 pre-terminated SC-APC (10 in W x 9 in H x 3 in D).	
SNID-F616ANAN9N-CL	16-port SNID Legacy Splitter Enclosure, two 1x8 pre-terminated SC-APC (10 in W x 9 in H x 3 in D).	
SFIT-FT04AGC	4-port Splitter Enclosure, 1x4 pre-terminated SC-APC, tall slack storage, U-shape lay-in grommets, single tie down ground lug, cable ties and bases (10 in W x 18 in H x 5 in D).	
SFIT-FT04AGC-002	4-port Splitter Enclosure, 1x4 pre-terminated SC-APC, tall slack storage, single tie down ground lug, 2-port F1 nozzle; 24-port 8.5mm F2 nozzle, cable ties and bases (10 in W x 18 in H x 5 in D).	
SFIT-FT04AGC-003	4-port Patch and Splice Splitter Enclosure, 1x4 pre-terminated SC-APC, two 12/24F splice trays, one set of 12F color-coded 900u pigtailed, medium slack storage, U-shape lay-in grommets, single tie down ground lug, cable ties and bases (10 in W x 18 in H x 5 in D).	
SFIT-FT08AGC	8-port Splitter Enclosure, 1x8 pre-terminated SC-APC, tall slack storage, U-shape lay-in grommets, single tie down ground lug, cable ties and bases (10 in W x 18 in H x 5 in D).	
SFIT-FT08AGC-002	8-port Splitter Enclosure, 1x8 pre-terminated SC-APC, tall slack storage, single tie down ground lug, 2-port F1 nozzle; 24-port 8.5mm F2 nozzle, cable ties and bases (10 in W x 18 in H x 5 in D).	

## Splitter Enclosures (cont.)

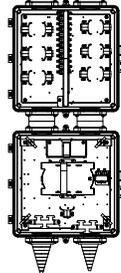
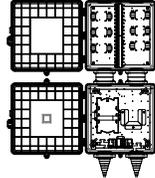
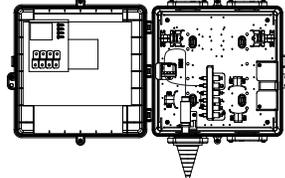
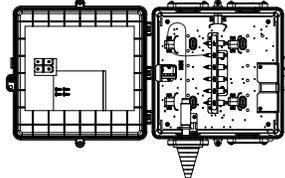
Part Number	Description	
SFIT-FT08AGC-003	8-port Patch and Splice Splitter Enclosure, 1x8 pre-terminated SC-APC, two 12/24F splice trays, one set of 12F color-coded 900u pigtails, medium slack storage, U-shape lay-in grommets, single tie down ground lug, cable ties and bases (10 in W x 18 in H x 5 in D).	
SFIT-FL16AGC	16-port Splitter Enclosure, 1x16 pre-terminated SC-APC, U-shape lay-in grommets, double-stack rubber grommets, single tie down ground lug, cable ties and bases (10 in W x 9 in H x 5 in D). Can add onto existing SFIT enclosures.	
SFIT-FT16AGC	16-port Splitter Enclosure, 1x16 pre-terminated SC-APC, tall slack storage, U-shape lay-in grommets, single tie down ground lug, cable ties and bases (10 in W x 18 in H x 5 in D).	
SFIT-FT16AGC-002	16-port Splitter Enclosure, 1x16 pre-terminated SC-APC, tall slack storage, single tie down ground lug, 2-port F1 nozzle; 24-port 8.5mm F2 nozzle, cable ties and bases (10 in W x 18 in H x 5 in D).	
SFIT-FT16AGC-003	16-port Patch and Splice Splitter Enclosure, 1x16 pre-terminated SC-APC, two 12/24F splice trays, two sets of 12F color-coded 900u pigtails, medium slack storage, U-shape lay-in grommets, single tie down ground lug, cable ties and bases (10 in W x 18 in H x 5 in D).	
SFIT-FL32AGC	32-port Splitter Enclosure, 1x32 pre-terminated SC-APC, U-shape lay-in grommets, double-stack rubber grommets, single tie down ground lug, cable ties and bases (10 in W x 9 in H x 5 in D). Can add onto existing SFIT enclosures.	
SFIT-FT32AGC	32-port Splitter Enclosure, 1x32 pre-terminated SC-APC, tall slack storage, U-shape lay-in grommets, single tie down ground lug, cable ties and bases (10 in W x 18 in H x 5 in D).	
SFIT-FT32AGC-001	32-port Splitter Enclosure, 1x32 pre-terminated SC-APC, tall slack storage, single tie down ground lug, 2-port F1 nozzle; 24-port 10mm F2 nozzle, cable ties and bases (10 in W x 18 in H x 5 in D).	
SFIT-FT32AGC-002	32-port Splitter Enclosure, 1x32 pre-terminated SC-APC, tall slack storage, single tie down ground lug, 2-port F1 nozzle; 24-port 8.5mm F2 nozzle, cable ties and bases (10 in W x 18 in H x 5 in D).	

## Splitter Enclosures (cont.)

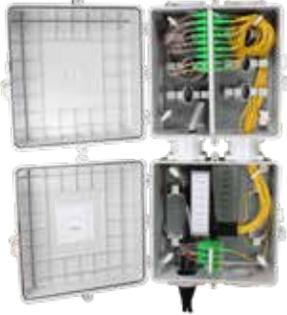
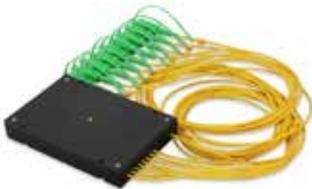
Part Number	Description
SFIT-FT32AGC-003	32-port Patch and Splice Splitter Enclosure, 1x32 pre-terminated SC-APC, two 12/24F splice trays, three sets of 12F color-coded 900u pigtails, medium slack storage, U-shape lay-in grommets, single tie down ground lug, cable ties and bases (10 in W x 18 in H x 5 in D).
APL102-PTJNC1-5	Splitter Integrated Mini Component 1x2 900u No Connectors 1.5 Meter leads (7 mm W x 4 mm H x 60 mm L).
APL104-PTJNC1-5	Splitter Integrated Mini Component 1x4 900u No Connectors 1.5 Meter leads (7 mm W x 4 mm H x 60 mm L).
APL108-PTJNC1-5	Splitter Integrated Mini Component 1x8 900u No Connectors 1.5 Meter leads (7 mm W x 4 mm H x 60 mm L).
SFSM-9M1102AA10M	Splitter Integrated Mini Component 1x2 900u SC-APC Connectors 1 Meter leads (7 mm W x 4 mm H x 60 mm L).
SFSM-9M1104AA10M	Splitter Integrated Mini Component 1x4 900u SC-APC Connectors 1 Meter leads (7 mm W x 4 mm H x 60 mm L).
SFSM-9M1108AA10M	Splitter Integrated Mini Component 1x8 900u SC-APC Connectors 1 Meter leads (7 mm W x 4 mm H x 60 mm L).
SFSM-9M1116AA10M	Splitter Integrated Mini Component 1x16 900u SC-APC Connectors 1 Meter leads (12 mm W x 4 mm H x 60 mm L).
SFSM-9M1132AA10M	Splitter Integrated Mini Component 1x32 900u SC-APC Connectors 1 Meter leads (20 mm W x 6 mm H x 60 mm L).



# Fiber Hubs

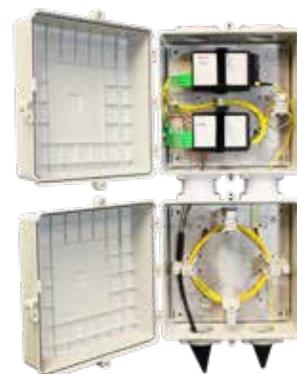
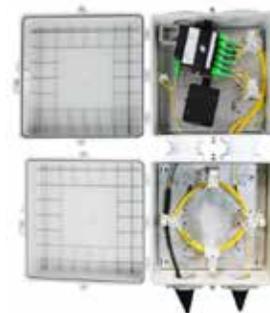
Part Number	Description	
UCS-FS72AENE-JB	24-port SC-APC (expandable to 72), one 12/24F splice tray, 4 SC input ports, slack storage, F1 inner cover, three 1.2-inch Closed Cap ports, one Rubber Cone Grommet port, holds 3 box-type splitters (14 in W x 14 in H x 8 in D).	
UCS-FS72AS4N-CL	36-port SC-APC (expandable to 72), four 12/24F splice trays, four 12F breakout cables, 3 SC input ports, slack storage, three 1.2-inch Closed Cap ports, one Rubber Cone Grommet port, pedestal mounting brackets, holds 3 box-type splitters (14 in W x 14 in H x 8 in D).	
UCS-FS72AS4D-CL	36-port SC-APC (expandable to 72), four 12/24F splice trays, four 12F breakout cables, 3 SC input ports, slack storage, three 1.2-inch Closed Cap ports, one Rubber Cone Grommet port, pedestal mounting brackets, one 1x32 splitter, holds 3 box-type splitters (14 in W x 14 in H x 8 in D).	
UCS-FD72AS9E	72-port SC-APC, eight 12/24F splice trays, six 12F breakout cables, six 1F pigtails, 14 SC input ports, slack storage, two 12-port Closed Cap port, two Rubber Cone Grommet ports, holds 6 box-type splitters (14 in W x 30 in H x 8 in D).	
FHP-D24072AS2E-CL	72-port SC-APC, eight 12/24F splice trays, eight 12F breakout cables, 26 SC input ports, slack storage, two 12-port Closed Cap ports, two Rubber Cone Grommet ports, holds 3 box-type splitters (14 in W x 30 in H x 8 in D).	
FHP-D24096ASNE	96-port SC-APC, eight 12/24F splice trays, 26 SC input ports, slack storage, two 12-port Closed Cap ports, two Rubber Cone Grommet ports, holds 3 box-type splitters (14 in W x 30 in H x 8 in D).	
UCS-FD144ASNE	144-port SC-APC, eight 12/24F splice trays, 14 SC input ports, slack storage, two 12-port Closed Cap port, two Rubber Cone Grommet ports, holds 6 box-type splitters (14 in W x 30 in H x 8 in D).	
UCS-FS72AXNNB-001	72-port SC-APC with one single 100ft 72F cable stub; narrow SC bulkhead in the bottom center, three 1.2-inch Closed Cap ports, one Rubber Cone Grommet port, holds 3 box-type splitters (14 in W x 14 in H x 8 in D).	
UCS-FS72AXNNB-002	72-port SC-APC with one single 100ft 72F cable stub; wide SC bulkhead in the center, three 1.2-inch Closed Cap ports, one Rubber Cone Grommet port, holds 3 box-type splitters (14 in W x 14 in H x 8 in D).	

## Fiber Hubs (cont.)

Part Number	Description	
FHP-D24072AXEEB-CL FHP-D24072AXEEN-CL (no stubs)	72-port SC-APC (expandable to 144), 50ft cable stubs, 32 SC input ports, slack storage, three 12-port Closed Cap ports, one Rubber Cone Grommet port, holds 9 box-type splitters (14 in W x 30 in H x 8 in D).	
FHP-D24096AXEEB-CL FHP-D24096AXEEN-CL (no stubs)	96-port SC-APC (expandable to 144), 50ft cable stubs, 32 SC input ports, slack storage, three 12-port Closed Cap ports, one Rubber Cone Grommet port, holds 9 box-type splitters (14 in W x 30 in H x 8 in D).	
FHP-D24144AXEEB-CL FHP-D24144AXEEN-CL (no stubs)	144-port SC-APC, 50ft cable stubs, 32 SC input ports, slack storage, three 12-port Closed Cap ports, one Rubber Cone Grommet port, holds 9 box-type splitters (14 in W x 30 in H x 8 in D).	
UCS-FD192AXXXN	144-port SC-APC, 48 SC input ports, slack storage, two 1.2-inch Closed Cap ports, two Rubber Cone Grommet ports, holds 18 box-type splitters (14 in W x 30 in H x 8 in D).	
FHM-D24216AXEEB-CL	216-port SC-APC, 50ft cable stubs, 38 SC input ports, holds 21 box-type splitters, 24F In 72F + 144F Out (25 in W x 46 in H x 10 in D) Indoor Only.	
FHM-D24288AXEEB-CL	288-port SC-APC, 50ft cable stubs, 38 SC input ports, holds 21 box-type splitters, 24F In 144F + 144F Out (25 in W x 46 in H x 10 in D) Indoor Only.	
FHM-D24360AXEEB-CL	360-port SC-APC, 50ft cable stubs, 38 SC input ports, holds 21 box-type splitters, 24F In 72F + 144F + 144F Out (25 in W x 46 in H x 10 in D) Indoor Only.	
FHM-D24432AXEEB-CL	432-port SC-APC, 50ft cable stubs, 38 SC input ports, holds 21 box-type splitters, 24F In 144F + 144F + 144F Out (25 in W x 46 in H x 10 in D) Indoor Only.	
SFSM-2B1102AA1M	Box Type Splitter Module 1x2 pre-terminated SC-APC 1 Meter (80 mm W x 10 mm H x 100 mm L).	
SFSM-2B1104AA1M	Box Type Splitter Module 1x4 pre-terminated SC-APC 1 Meter (80 mm W x 10 mm H x 100 mm L).	
SFSM-2B1108AA1M	Box Type Splitter Module 1x8 pre-terminated SC-APC 1 Meter (80 mm W x 10 mm H x 100 mm L).	
SFSM-2B1116AA1M	Box Type Splitter Module 1x16 pre-terminated SC-APC 1 Meter (80 mm W x 18 mm H x 120 mm L).	
SFSM-2B1132AA1M	Box Type Splitter Module 1x32 pre-terminated SC-APC 1 Meter (80 mm W x 18 mm H x 120 mm L).	
SFSM-2B1164AA1M	Box Type Splitter Module 1x64 pre-terminated SC-APC 1 Meter (115 mm W x 18 mm H x 140 mm L).	

## Fiber Hubs (cont.)

Part Number	Description
UFDH-00AAND-001	1UCS Empty Splitter Enclosure, goal post brackets (holds four 1x32; six 1x16; twelve 1x8 or 1x4 or 1x2 splitter modules), two 1.2-ich Closed Cap ports and two Rubber Cone Grommet ports (14 in W x 14 in H x 8 in D). Can be added onto an existing UCS Enclosure.
UFDH-00AAND	2UCS Empty Splitter Enclosure, goal post brackets (holds four 1x32; six 1x16; twelve 1x8 or 1x4 or 1x2 splitter modules), slack storage, two 1.2-ich Closed Cap ports and two Rubber Cone Grommet ports (14 in W x 30 in H x 8 in D).
UFDH-64AAND	64-port SC-APC, two 1x32 Splitter Modules (holds four 1x32 splitters or six 1x16 splitters for 128ports), slack storage, two 1.2-ich Closed Cap ports and two Rubber Cone Grommet ports (14 in W x 30 in H x 8 in D).
UFDH-00AMND-001	1UCS Empty Splitter Enclosure, brackets for SFSM-C396AMA or SFSM-C412AAA Splitter Modules (holds ten splitter modules), two 1.2-ich Closed Cap ports and two Rubber Cone Grommet ports (14 in W x 14 in H x 8 in D). Can be added onto an existing UCS Enclosure.
UFDH-00AMND	2UCS Empty Splitter Enclosure, brackets for SFSM-C396AMA or SFSM-C412AAA Splitter Modules (holds ten splitter modules), slack storage, two 1.2-ich Closed Cap ports and two Rubber Cone Grommet ports (14 in W x 30 in H x 8 in D).
UFDH-96AMND	96F (expandable to 672F) with one SFSM-C396AMA Splitter Module (holds ten splitter modules), slack storage, two 1.2-ich Closed Cap ports and two Rubber Cone Grommet ports. SC-APC inputs; 12F MPO outputs (14 in W x 30 in H x 8 in D).
UFDH-192AMND-2	192F (expandable to 672F) with two SFSM-C396AMA Splitter Modules (holds ten splitter modules), slack storage, two 1.2-ich Closed Cap ports and two Rubber Cone Grommet ports. SC-APC inputs; 12F MPO outputs (14 in W x 30 in H x 8 in D).
UFDH-192AMND	192F (expandable to 672F) with one SFSM-C412AAA and two SFSM-C396AMA Splitter Modules for 1x64 cascaded split ratio (holds ten splitter modules), slack storage, two 1.2-ich Closed Cap ports and two Rubber Cone Grommet ports. SC-APC inputs; 12F MPO outputs (14 in W x 30 in H x 8 in D).
UFDH-288AMND	288F (expandable to 672F) with one SFSM-C412AAA and three SFSM-C396AMA Splitter Modules for 1x64 cascaded split ratio (holds ten splitter modules), slack storage, two 1.2-ich Closed Cap ports and two Rubber Cone Grommet ports. SC-APC inputs; 12F MPO outputs (14 in W x 30 in H x 8 in D).
UFDH-384AMND	384F (expandable to 672F) with two SFSM-C412AAA and four SFSM-C396AMA Splitter Modules for 1x64 cascaded split ratio (holds ten splitter modules), slack storage, two 1.2-ich Closed Cap ports and two Rubber Cone Grommet ports. SC-APC inputs; 12F MPO outputs (14 in W x 30 in H x 8 in D).



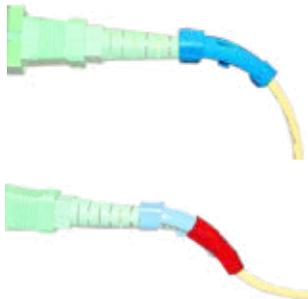
## Fiber Hubs (cont.)

Part Number	Description	
SFSM-C396AMA	96F Splitter Module (three 1x32) with three SC-APC input ports, eight 12F MPO pinned output ports.	
SFSM-C412AAA	8F Splitter Module (four 1x2) with four SC-APC input ports, eight 1F SC-APC outputs 0.5 meter (cascade into 1x32 splitters to create 1x64 split ratios).	

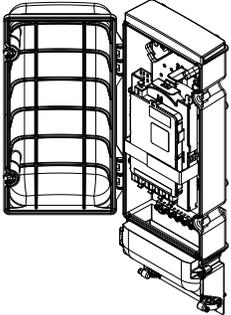
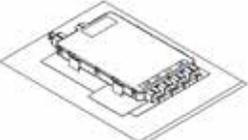
## MPO - MPO Cables for Density-Optimized Fiber Networks

Part Number	Length (ft)	Description	
AU12-E-PF/PF-100-R	100		
AU12-E-PF/PF-200-R	200		
AU12-E-PF/PF-300-R	300		
AU12-E-PF/PF-400-R	400		
AU12-E-PF/PF-500-R	500	Cables have 12-fiber MPO connectors (female) at each end. Pulling eye and protective sock at each end.	
AU12-E-PF/PF-600-R	600	Cable is 12-fiber, indoor/outdoor, LSZH OFNR riser-rated, 5mm diameter.	
AU12-E-PF/PF-700-R	700		
AU12-E-PF/PF-800-R	800		
AU12-E-PF/PF-900-R	900		
AU12-E-PF/PF-1000	1000		

## Fiber Markers

Part Number	Description	
FMK-1001-VZ	Fiber Marker ID Kit for patch cords. Markers attach to 2mm or 3mm cords to help identify routing. Kit includes: 14 standard colors (33 markers each), 32 special service caps, one identification label, and one plastic case.	
FML-1001-VZ	Fiber Marker Labels, self-adhesive 15-color table for splitter identification A-N and Special Service Cap (10 per pack).	
FM-BLP032BL-VZ	Replacement Markers, bag of 33. Color: Blue.	
FM-ORP032BL-VZ	Replacement Markers, bag of 33. Color: Orange.	
FM-GRP032BL-VZ	Replacement Markers, bag of 33. Color: Green.	
FM-BRP032BL-VZ	Replacement Markers, bag of 33. Color: Brown.	
FM-SLP032BL-VZ	Replacement Markers, bag of 33. Color: Slate.	
FM-WHP032BL-VZ	Replacement Markers, bag of 33. Color: White.	
FM-RDP032BL-VZ	Replacement Markers, bag of 33. Color: Red.	
FM-BKP032BL-VZ	Replacement Markers, bag of 33. Color: Black.	
FM-YLP032BL-VZ	Replacement Markers, bag of 33. Color: Yellow.	
FM-VTP032BL-VZ	Replacement Markers, bag of 33. Color: Violet.	
FM-RSP032BL-VZ	Replacement Markers, bag of 33. Color: Rose.	
FM-AQP032BL-VZ	Replacement Markers, bag of 33. Color: Aqua.	
FM-DBP032BL-VZ	Replacement Markers, bag of 33. Color: Dark Blue.	
FM-DGP032BL-VZ	Replacement Markers, bag of 33. Color: Dark Green.	
FMS-RDP032-VZ	Replacement Special Service Cap, bag of 32. Color: Dark Red.	

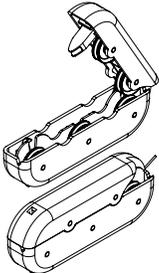
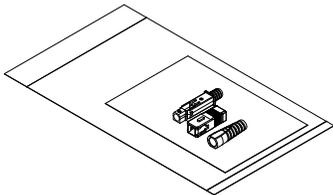
# Pedestal Terminals

Part Number	Description	
PAT-SP12AXX	Pedestal Terminal 12-port Patch Only SC-APC, two (0.6-inch max) cable ports with two single ground lugs, easy lay-in grommets for twelve round or flat drops with twelve strength member tie downs, dual 216c captive screws, pole/pedestal/wall mount bracket, supports mid-span access (6 in W x 17 in H x 3.5 in D).	
PAT-SB04AXX-1X4	Pedestal Terminal 4-port Patch and Splice with 1x4 SC-APC Splitter Module, 12/24F splice tray, two (0.6-inch max) cable ports with two single tie down ground lugs, easy lay-in grommets for twelve round or flat drops with twelve strength member tie downs, dual 216c captive screws, pole/pedestal/wall mount bracket, supports mid-span access (6 in W x 17 in H x 4.5 in D).	
PAT-SB06AXX	Pedestal Terminal 6-port Patch and Splice SC-APC, 6F SC-APC breakout cable, 12/24F splice tray, two (0.6-inch max) cable ports with two single tie down ground lugs, easy lay-in grommets for twelve round or flat drops with twelve strength member tie downs, dual 216c captive screws, pole/pedestal/wall mount bracket, supports mid-span access (6 in W x 17 in H x 4.5 in D).	
PAT-SB12AXX	Pedestal Terminal 12-port Patch and Splice SC-APC, 12F SC-APC breakout cable, 12/24F splice tray, two (0.6-inch max) cable ports with two single tie down ground lugs, easy lay-in grommets for twelve round or flat drops with twelve strength member tie downs, dual 216c captive screws, pole/pedestal/wall mount bracket, supports mid-span access (6 in W x 17 in H x 4.5 in D).	
PAT-SS12XXX	Pedestal Terminal Splice Only, 12/24F splice tray, two (0.6-inch max) cable ports with two single tie down ground lugs, easy lay-in grommets for twelve round or flat drops with twelve strength member tie downs, dual 216c captive screws, pole/pedestal/wall mount bracket, supports mid-span access (6 in W x 17 in H x 3.5 in D).	
PAT-SS12XXX-001	Pedestal Terminal Splice Only, 12/24F splice tray (room for 2), two (0.6-inch max) cable ports with two single tie down ground lugs, easy lay-in grommets for twelve round or flat drops with twelve strength member tie downs, dual 216c captive screws, pole/pedestal/wall mount bracket, supports mid-span access (6 in W x 17 in H x 4.5 in D).	
SFSM-C1104AA-P	Stackable Splitter Module for Pedestal Terminals, 1x4 SC-APC (stackable on itself or any SFSM-24SFC Splice Tray).	
PAT-PMB	Pole Mount Bracket, replacement kit for Pedestal Terminals.	

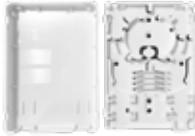
 
 
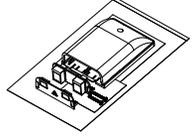
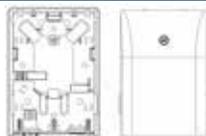
# PPC QuikPass™ Solutions

Part Number	Description	
10-1429-03B	QuikPass™ Fiber Entry Box 2-pigtail 657.A2 with SC adapter, splice sleeves and mounting accessories (2.7 in W x 5.5 in L x 0.6 in H).	
10-1429-04B	QuikPass™ Fiber Entry Box 1-pigtail 657.A2 with SC adapter, splice sleeves and mounting accessories (2.7 in W x 5.5 in L x 0.6 in H).	
10-1429-05B	QuikPass™ Fiber Entry Box Basic Patch/Splice (no pigtails) with SC adapter, splice sleeves and mounting accessories (2.7 in W x 5.5 in L x 0.6 in H).	
AX110050	QuikPass™ Fiber Entry Hallway Poke-Thru Transition Kit	
10-1407	2mm Miniflex® Wall Clips, white (200 per kit)	
10-1408	3mm Miniflex® Wall Clips, white (200 per kit)	
10-1605	4mm Miniflex® Wall Clips, white (200 per kit)	
10-1409	8mm Miniflex® Wall Clips, white (200 per kit)	
10-0293	Rotary Cable / Tubing Cutter 8mm Miniflex®	
10-0291	Rotary Cable / Tubing Cutter 2mm/3mm Miniflex®	
10-0294	Tubing Cutter	
10-0295	Spare Blade for Tubing Cutter (10 per box)	
QPST-515	Tool, Window Shaving	
QPST-515-SB	Spare Blade for Window Shaving Tool	

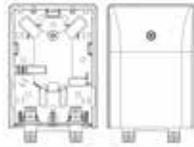
# PPC QuikPass™ Solutions (cont.)

Part Number	Description	
RSK-MINIFLEX	Ring and Slit Tool Kit, 3mm-10mm Miniflex®	
RSK-MINIFLEX-SB	Spare Blades for Ring and Slit Tool Kit	
MFS-23	Miniflex® Straightener Tool	
BRT-SC	Balistix™ Connector Removal Tool	
10-1321	Balistix™ SC-APC Spare Parts Kit (1EA = 25/PK)	
10-1322	Balistix™ SC-UPC Spare Parts Kit (1EA = 25/PK)	
10-1327	Small Customer Terminal, Surface Mount, one flanged SC-APC simplex adapter (room for 2), two splice sleeve holders, 6 feet (2 meter) of 3mm slack storage white (3.4 in H x 3.4 in W x 0.94 in D) 10 per box. Accepts microduct input.	
10-1328	Medium Customer Terminal, Surface Mount with removable splice tray (snaps into the wall mount base), one flanged SC-APC simplex adapter (room for 2), two splice sleeves, two large splice sleeve holders, 25 feet (8 meter) of 3mm slack storage, white (8 in H x 4.5 in W x 1.4 in D) 10 per box. Accepts microduct input.	
10-1343	Large Customer Terminal, Surface Mount with removable slack storage spool, one flanged SC-APC simplex adapter, one large splice sleeve holder for 2 splice sleeves, 50 feet (15 meter) of 3mm slack storage, white (7 in H x 6 in W x 1.7 in D) 10 per box. Accepts microduct input.	

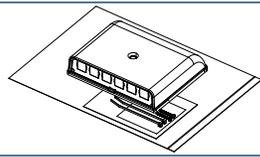
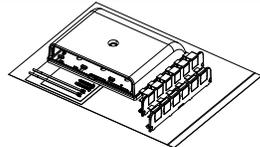
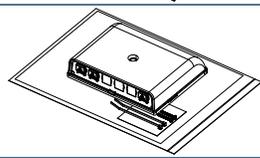
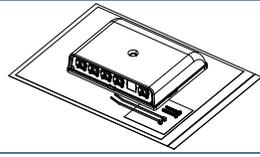
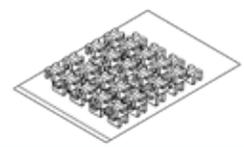
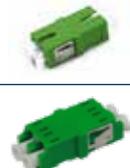
## Fiber Wall Plates and Accessories

Part Number	Description	
090442-00	Surface Mount Fiber Splice Case, 4F (3.3 in W x 4.6 in H x 0.7 in D) empty with one blank insert, white (accepts two SC simplex or two LC duplex adapters, sold separately)	
OSB-2SSA	2-port Surface Mount Fiber Wall Plate with shutters, two flanged SC-APC simplex adapters, two splice sleeves, 6 feet (2 meter) of 3mm slack storage white (3.4 in H x 3.4 in W x 1.0 in D)	
CON-13X5-00	Surface Mount Fiber Wall Plate, Dual Cover (3.5 in W x 6.1 in H x 1.2 in D) empty (no adapters), two rubber grommets, white	
CON-4447-85XXX	Surface Mount Fiber Wall Plate, Single Cover (3.5 in W x 4.9 in H x 1.2 in D) empty (no adapters), two blank inserts, white	
CON-4447-85KEY	Surface Mount Fiber Wall Plate, Single Cover (3.5 in W x 4.9 in H x 1.2 in D) empty (no adapters), two blank inserts, white for Keystone	
CON-4447-85KEY-SX	Surface Mount Fiber Wall Plate, Single Cover (3.5 in W x 4.9 in H x 1.2 in D) empty (no adapters), two blank inserts, white for flangeless SC Simplex or LC Duplex or Keystone	
CON-13X5-85 (APC) CON-13X5-85U (UPC)	1-port Surface Mount Fiber Wall Plate, Dual Cover (3.5 in W x 6.1 in H x 1.2 in D) one internal SC adapter (room for 2), one rubber grommet, white	
CON-133A-85PR (APC) CON-133A-85PRU (UPC)	2-port Surface Mount Fiber Wall Plate, Dual Cover (3.5 in W x 6.1 in H x 1.2 in D) two internal SC adapters, two rubber grommets, white	
CON-13X6-85 (APC) CON-13X6-85U (UPC)	1-port Surface Mount Fiber Wall Plate, Dual Cover (3.5 in W x 6.1 in H x 1.2 in D) one external 45-degree angle shuttered SC adapter, one blank insert, white	
CON-44X7-85 (APC) CON-44X7-85U (UPC)	1-port Surface Mount Fiber Wall Plate, Single Cover (3.5 in W x 4.9 in H x 1.2 in D) one external shuttered SC adapter (room for 2), one blank insert, white	
CON-44X7-85LD (APC) CON-44X7-85LDU (UPC)	2-port Surface Mount Fiber Wall Plate, Single Cover (3.5 in W x 4.9 in H x 1.2 in D) one external LC Duplex adapter (room for 2), one blank insert, white	

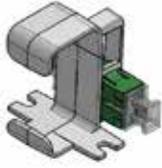
 
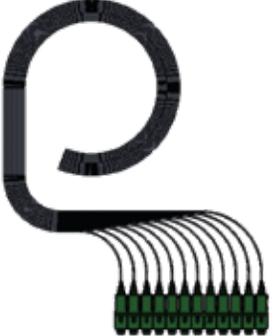
## Fiber Wall Plates and Accessories (cont.)

Part Number	Description	
CON-4447-85AT (APC) CON-4447-85U (UPC)	2-port Surface Mount Fiber Wall Plate, Single Cover (3.5 in W x 4.9 in H x 1.2 in D) two external shuttered SC adapters, white	
CON-4447-85ANS (APC) CON-4447-85UNS (UPC)	2-port Surface Mount Fiber Wall Plate, Single Cover (3.5 in W x 4.9 in H x 1.2 in D) two external SC adapters, white	
CON-4447-85LD (APC) CON-4447-85LDU (UPC)	4-port Surface Mount Fiber Wall Plate, Single Cover (3.5 in W x 4.9 in H x 1.2 in D) two external LC Duplex adapters, white	
WPKW1VO	1-port Keystone Wall Plate, empty (no inserts), white	
WPKW2VOB	2-port Keystone Wall Plate, empty (no inserts), one blank, white	
WPKW3VOBB	3-port Keystone Wall Plate, empty (no inserts), two blanks, white	
CF81GHZMKEYW	Keystone Insert F-81 Coax white (CATV)	
WPKEYW6RJ45	Keystone Insert Cat.6 white (data)	
WPKEYW5ERJ45	Keystone Insert Cat.5e white (data)	
WPKEYWRJ11	Keystone Insert RJ11 white (phone)	
WPKEYWBLANK	Keystone Insert Blank white	
WPKEYWSCUS WPKEYWSCGS (APC) WPKEYWSCBS (UPC)	Keystone Insert White SC Simplex Shuttered white Keystone Insert Green SC Simplex Shuttered white Keystone Insert Blue SC Simplex Shuttered white	
WPKEYWSCG (APC) WPKEYWSCB (UPC) WPKEYWSCGINT (APC) WPKEYWSCBINT (UPC)	Keystone Insert Green SC Simplex white Keystone Insert Blue SC Simplex white Keystone Insert Green SC Simplex Internal Laser Shutter white Keystone Insert Blue SC Simplex Internal Laser Shutter white	
WPKEYWLDG (APC) WPKEYWLDB (UPC) WPKEYWLDGINT (APC) WPKEYWLDBINT (UPC)	Keystone Insert Green LC Duplex white Keystone Insert Blue LC Duplex white Keystone Insert Green LC Duplex Internal Laser Shutter white Keystone Insert Blue LC Duplex Internal Laser Shutter white	

## Fiber Wall Plates and Accessories (cont.)

Part Number	Description	
CON-21X1-85 (APC) CON-21X1-85U (UPC)	1-port Surface Mount Fiber Wall Plate, Double Wide (6.7 in W x 5.5 in H x 1.5 in D) three coax, two blank insert, one external shuttered SC adapter (room for 3), white	
CON-2221-85	Surface Mount Fiber Wall Plate, 6port Double Wide, White (6.7 in W x 5.5 in H x 1.5 in D) for FutureLink	
CON-2221-85KEY	Surface Mount Fiber Wall Plate, 6port Double Wide, White (6.7 in W x 5.5 in H x 1.5 in D) for Keystone	
CON-2221-85KEY-SS	Surface Mount Fiber Wall Plate, 6port Double Wide, White (6.7 in W x 5.5 in H x 1.5 in D) for FutureLink or Keystone	
CON-2221-85-1X2	Surface Mount Fiber Wall Plate, 3port Double Wide, White (6.7 in W x 5.5 in H x 1.5 in D) with 1x2 PLC Splitter for FutureLink	
CON-2221-85-1X4	Surface Mount Fiber Wall Plate, 5port Double Wide, White (6.7 in W x 5.5 in H x 1.5 in D) with 1x4 PLC Splitter for FutureLink	
CON-GRMKIT-20	Port Grommet Kit (20 Ea) for CON-13X5 and CON-133A Wall Plates	
STAR500SCGR-T-85K (Green) STAR500SCBL-T-85K (Blue) STAR500SCBK-T-85K (Black)	Adapter Kit, SC Simplex Shuttered for CON-13X6; CON-21X1; CON-2221, White (4 per pack)	
STAR500LCGR-T-85K (Green) STAR500LCBL-T-85K (Blue)	Adapter Kit, LC Duplex Shuttered for CON-13X6; CON-21X1; CON-2221, White (4 per pack)	
ADPSCA6 (Green) ADPSCB6 (Black) ADPSCU6 (Blue)	Adapter Kit, SC Simplex, No Flange, 6 per pack	
ADPLCA6 (Green) ADPLCU6 (Blue)	Adapter Kit, LC Duplex, No Flange, 6 per pack	
AX100222 (Black)	12-port / 24-port Multi-User Outlet Box Empty with One Solid Blank Panel (one side is open). Install one or two each 12-port Keystone Adapter Plates (AX104615) sold separately.	
AX104615 (Black)	12-port Multi-User Outlet Box Keystone Adapter Plate for 12 Keystone Inserts	

 
## Fiber Wall Plates and Accessories (cont.)

Part Number	Description	
SFIT-ADP-KIT-1 (Green) SFIT-ADP-KIT-2 (Blue)	Adapter Mounting Kit, 2port frame with one SC adapter and mounting screws (sold 1 each)	
SFIT-ADP-KIT-3 (Green) SFIT-ADP-KIT-4 (Blue)	Adapter Mounting Kit, 2port frame with two SC adapters and mounting screws (sold 1 each)	
ADPMTNSCA (Green) ADPMTNSCU (Blue)	Adapter Mounting Kit, 1port frame with one SC adapter, splice chips, base, mounting screws (sold 10 per pack)	
PTSCAA1-09-TLYE-1	1F Pigtail, 900um 657.A1 SC-APC Short Boot to blunt, 1 meter tight buffer yellow.	
PTSCAA2-09-TLYE-1	1F Pigtail, 900um 657.A2 SC-APC Short Boot to blunt, 1 meter tight buffer yellow.	
● PTSCAA1-09-12F10US	12F Pigtail, 900um 657.A1 SC-APC Short Boot to blunt, 1 meter tight buffer color coded.	
● PTSCAA1-09-12F20US	12F Pigtail, 900um 657.A1 SC-APC Short Boot to blunt, 2 meter tight buffer color coded.	
● PTSCUA1-09-12F10US	12F Pigtail, 900um 657.A1 SC-UPC Short Boot to blunt, 1 meter tight buffer color coded.	
● PTSCUA1-09-12F20US	12F Pigtail, 900um 657.A1 SC-UPC Short Boot to blunt, 2 meter tight buffer color coded.	
AU01-E-ZA/X-006F-T	1F Pigtail, 2mm 657.A1 SC-APC to blunt, 6ft yellow jacket	
AU01-E-ZA/X-006F-S	1F Pigtail, 3mm 657.A1 SC-APC to blunt, 6ft black jacket	

● **BABA compliant options available**



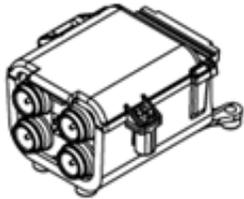
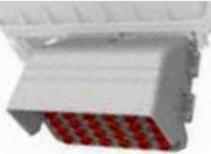
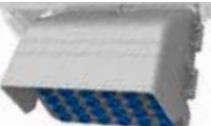
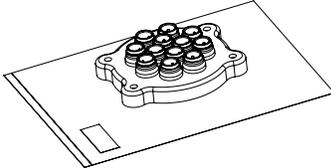
## Fiber Wall Plates and Accessories (cont.)

Part Number	Description	
AU01-E-ZA/ZA-015FS	1F Jumper, 3mm 657.A1 SC-APC to SC-APC, 15ft black jacket	
RFO-12-SCA	12F Ribbon Fanout, 12 SC-APC, 6 foot	
SFST-12-SCA-LT	12F Loose Tube Fanout, 12 SC-APC Bulkhead on 24F Splice Tray	
SFST-12-SCA-RFO	12F Ribbon Fanout, 12 SC-APC Bulkhead on 12/24F splice tray with Splice Chip	
SFST-12SF	12F Splice Tray, Single Layer, Thin Profile, Clear Cover	
SFST-24SFC	12/24F Slice Tray, Double Layer, Standard Profile, Splice Chip, Stackable Bases	
STCONVKIT-24	Splice Tray Conversion Kit for SFIT, 12/24F Standard Splice Tray and Mounts, 2-inch Fiber Routers, Single tie down ground lug.	

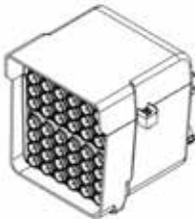
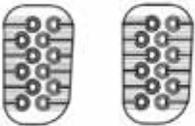
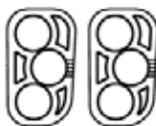
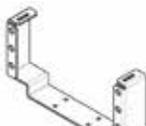
## Accessories

Part Number	Description	
SFIT-NOZ-HFOC-1L	SFIT Nozzle SC Simplex HFOC (lower), 1-3 per SFIT	
SFIT-NOZ-2GRMT-10	SFIT Nozzle Dual Port Feed (lower), two 0.7-inch diameter rubber grommets, 1-3 per SFIT	
SFIT-NOZ-DGRMT-10	SFIT Nozzle Dual Port Distribution (lower), two 12port 5mm rubber grommets, 1-3 per SFIT	
SFIT-NOZ-COND-1L-1	SFIT Nozzle 1.25-inch PVC Conduit (lower), 1-3 per SFIT	
SFIT-NOZ-COND-1U-1	SFIT Nozzle 1.25-inch PVC Conduit (upper), 1-3 per SFIT	
SFIT-NOZ-TZD-CR075	SFIT Nozzle 0.75-inch Tall Trapezoid (lower) for CableReady, 1-3 per SFIT	
SFIT-NOZ-GMOLD-1TL	SFIT Nozzle 1-inch Tall Trapezoid (lower) for CableReady, 1-3 per SFIT	
SFIT-NOZ-GMOLD-3L	SFIT Nozzle, 3-inch Tall Gutter (lower) 3.25-inch Wide for Rectangular Cable Channel, 1 per SFIT	
SFIT-NOZ-VPT-10	SFIT Nozzle, Vertical Pass-through (upper), 1-3 per SFIT	

 
 
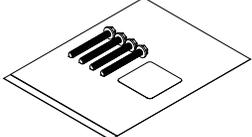
## Accessories (cont.)

Part Number	Description	
SFIT-NOZ-MICRO84P	SFIT Nozzle 4-port 8.5mm microduct (lower) with 4 BLUE couplers, 1-3 per SFIT	
SFIT-NOZ-MICRO104P	SFIT Nozzle 4-port 10mm microduct (lower) with 4 RED couplers, 1-3 per SFIT	
SFIT-NOZ-MICRO10L	SFIT Nozzle 24-port 10mm microduct (lower) with 24 RED couplers 1 per SFIT	
SFIT-NOZ-MICRO10U	SFIT Nozzle 24-port 10mm microduct (upper) with 24 RED couplers, 1 per SFIT	
SFIT-NOZ-MICRO8L	SFIT Nozzle 24-port 8.5mm microduct (lower) with 24 BLUE couplers, 1 per SFIT	
SFIT-NOZ-MICRO8U	SFIT Nozzle 24-port 8.5mm microduct (upper) with 24 BLUE couplers, 1 per SFIT	
MDO-10-02	Surface Mount 24-port 10mm Micro Duct Organizer with 24 RED microduct couplers and screws.	
MDO-08-02	Surface Mount 24-port 8.5mm Micro Duct Organizer with 24 BLUE microduct couplers and screws.	
UCS-NOZ-10MM-12	UCS Nozzle 12-port 10mm microduct port cap with 48 RED couplers, 1-4 per UCS	
UCS-NOZ-8MM-12	UCS Nozzle 12-port 8.5mm microduct port cap with 48 BLUE couplers, 1-4 per UCS	

 
 
## Accessories (cont.)

Part Number	Description	
UCS-NOZ-10MM-48	UCS Nozzle 48-port 10mm microduct with 48 RED couplers, 1-4 per UCS	
UCS-NOZ-8MM-48	UCS Nozzle 48-port 8.5mm microduct with 48 BLUE couplers, 1-4 per UCS	
SFIT-POLEMTG-10	SFIT Pole Mount Kit, with mounting hardware (1 each = 1 pair).	
SFIT-MEK24-VZ	SFIT Microduct Kit for SFIT-FL00BNX-001 Slack Storage Enclosure	
SFIT-GRMT-L-20	Replacement Bag of 20 Black Rubber Grommets for SFIT (1 each = 1 bag of 20)	
021445-00	Two 12-port 3mm rubber grommets for SFIT-NOZ-DGRMT-10 Nozzle	
SFIT-NOZ-GMT-12MM	Two 3-port 12mm / 0.5-inch Micro Duct Grommets for SFIT-NOZ-2GRMT-10 Nozzle	
UCS-STKIT-24F	12/24F Splice Tray + Mounting Bracket and Screws for UCS	
020669-00	SFIT Cable Spool Payout Kit for Terminals (Axle + Retainer Cap)	
020921-00	SFIT Cable Spool Payout Kit for Density-Optimized Terminals (Axle + Retainer Cap)	
031176-03	Surface-Mount Support Bracket for MPO Fanout Cassette Modules (SCM-12xCM2N)	

## Accessories (cont.)

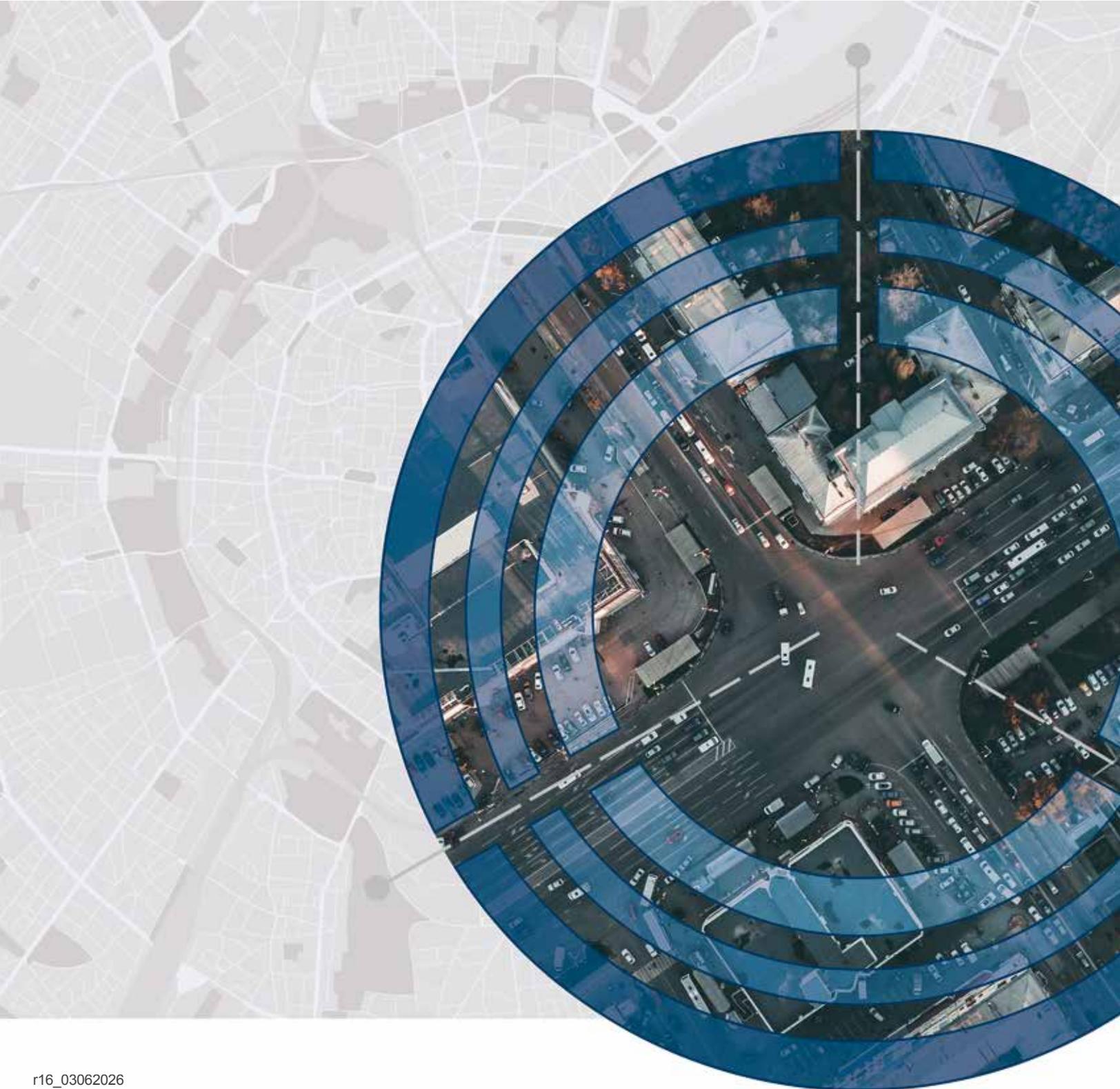
Part Number	Description	
010915-61	Plastic Surface-Mount Support Base for 1x2 or 1x4 or 1x8 Splitter Cassette Modules.	
021446-00	Three Double-Stack Rubber Grommets and six Screws for stacking two SFIT enclosures	
020189-00	SFIT Standoff Extension Feet (Set of 4)	
15183-01	Kit of FlexPON® Enclosure Accessories (4 Mounting Screws; 2 Rubber Grommets; 2 Hose Clamps and Grips; 2 Miniflex® Grommets; 1 Tie Down Ground Lug)	
14404-01	Mounting Screws (Set of 4)	
15876-01	Drywall Kit Anchors and Screws (Set of 4)	
021345-00	UCS Kit, Backboard Mounting Screws (Set of 4)	
021346-00	UCS Kit, External Mounting Brackets and Screws (Set of 4)	
UCS-BB	UCS Backboard (aluminum) with 0.25-inch holes in 1-inch square patterns and mounting screws for empty enclosure.	
UCS-C1	UCS Fiber Router / Slack Manager, 2.65 x 1.5 inch (Set of 4) with mounting screws	
UCS-C4	UCS Fiber Router / Slack Manager, 1.35 x 1.0 inch (Set of 4) with mounting screws	

## Accessories (cont.)

Part Number	Description	
UCS-G2	UCS Cone Grommet Kit (rubber cone + ring brush + port cap) with mounting screws	
SCC-UUF	UCS PVC Coupler Kit, 2.5-inch UCS to UCS. Kit couples one UCS port; order two kits to stack two UCS enclosures together. PVC tube can be cemented into port caps with standard PVC cement.	
SCC-2C	UCS Metal Coupler, 2-inch Metal Coupler for any UCS port (2-inch EMT compression fitting).	
UCS-PMB	UCS Pole Mount Bracket Kit, with mounting hardware, two lag screws, two 18-inch diameter adjustable stainless steel bands	
UCS-PED-FITS-KIT01	Pedestal Mount Bracket Kit for FITS or UCS Enclosures with mounting hardware.	
DISCONNECT-KIT-10	Customer Disconnect Kit with one SC Ferrule Dust Cover and one SC Adapter Dust Cap (1EA = 10 kits per bag).	

**Notes:**

---



r16\_03062026