

XFI44U2848-S004 OPEN BRIDGE RACK 44RU/400U x 28w x 48d

- 82.125h x 28w x 48d
- WELDED STEEL FRAME CONSTRUCTION w/ REINFORCED CORNER POSTS
- HEAVY DUTY CASTERS
- HEAVY DUTY LEVELING LEGS
- COLOR: CARDINAL WHITE (C031-WH120) SEMI GLOSS TEXTURE

- (2) PAIR FULLY ADJUSTABLE AND REVERSIBLE EIA/OCF RAILS 44RU/400U
- RAILS MOUNTED IN OCF CONFIGURATION
- SQUARE HOLE TYPE EIA SIDE FOR CAGE NUT
- (50) M6 MOUNTING HARDWARE INCLUDED
- RAIL FINISH IS CLEAR ZINC PLATED
- NUMERICAL MARKINGS FOR EACH RACK UNIT w/ UNIT 1 STARTING @ BOTTOM

- FULL SIZE 78% PERFORATED CONTOUR FRONT & REAR DOOR
- LOCKING SWING HANDLE
- CONTOUR PERFORATED DOORS ADD 2.60 INCHES (PER DOOR) TO FRAME DEPTH DIMENSION

- (3)PC TOP PANEL
- FRONT & REAR PANELS HAVE 5-1/4IN KNOCKOUTS
- CENTER PANEL IS SOLID
- ADDED (4) GROMMETS TO FRONT & REAR PANELS

- PARTIAL BOTTOM PANEL w/ REAR CABLE OPENING



- FLUSH MOUNTED SIDE PANELS w/ TAMPER RESISTANT SCREWS

- (2) VERTICAL LACING PANELS (OCF FRONT RAIL LOCATOR PANEL) MOUNTED IN FRONT

- (2) VERTICAL REAR LOCATION / POWER SHELF MOUNTING CHANNEL (OCF)

- BOTTOM FRONT SKIRT

- BOLT TOGETHER KIT w/ STRAP

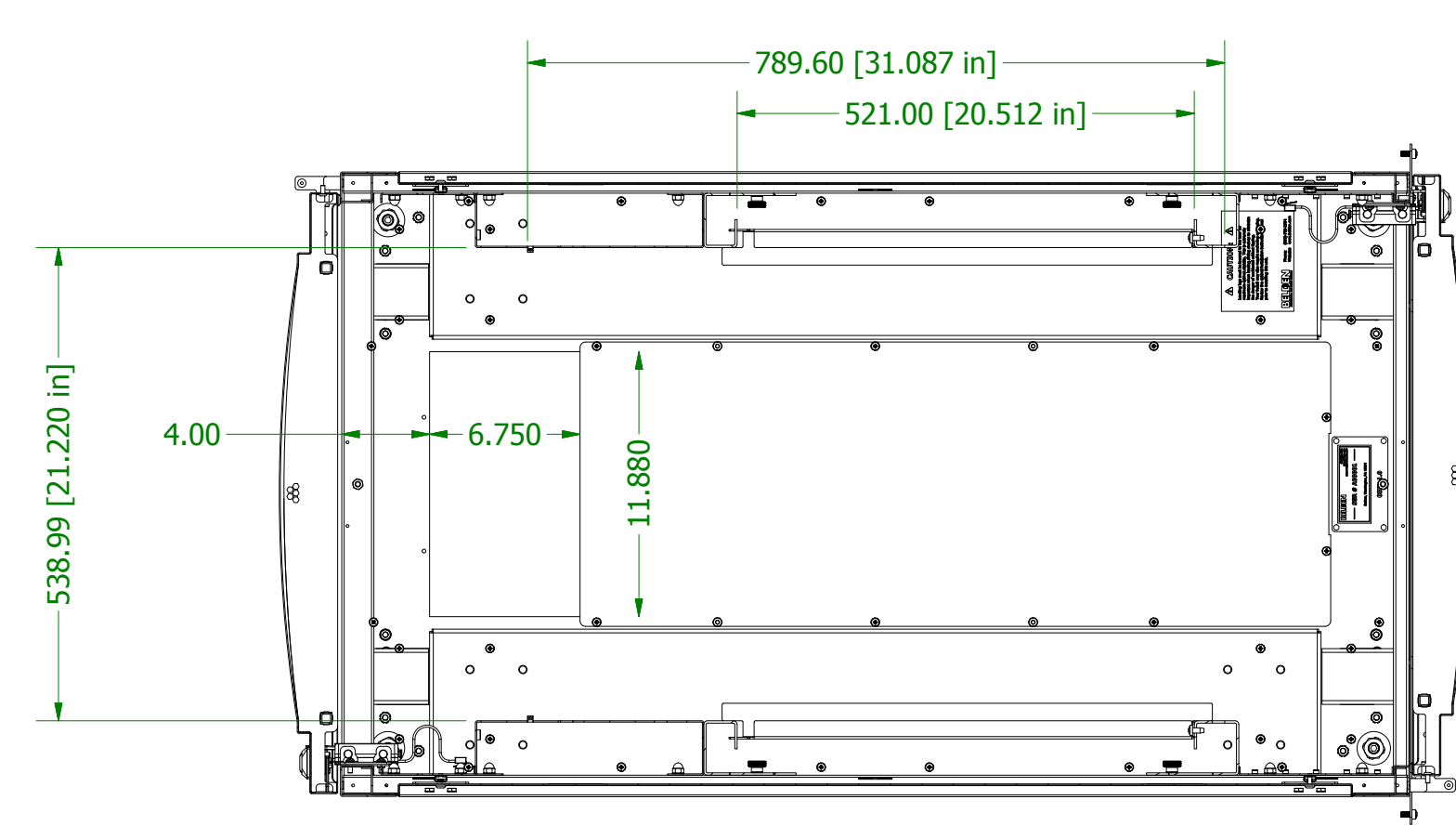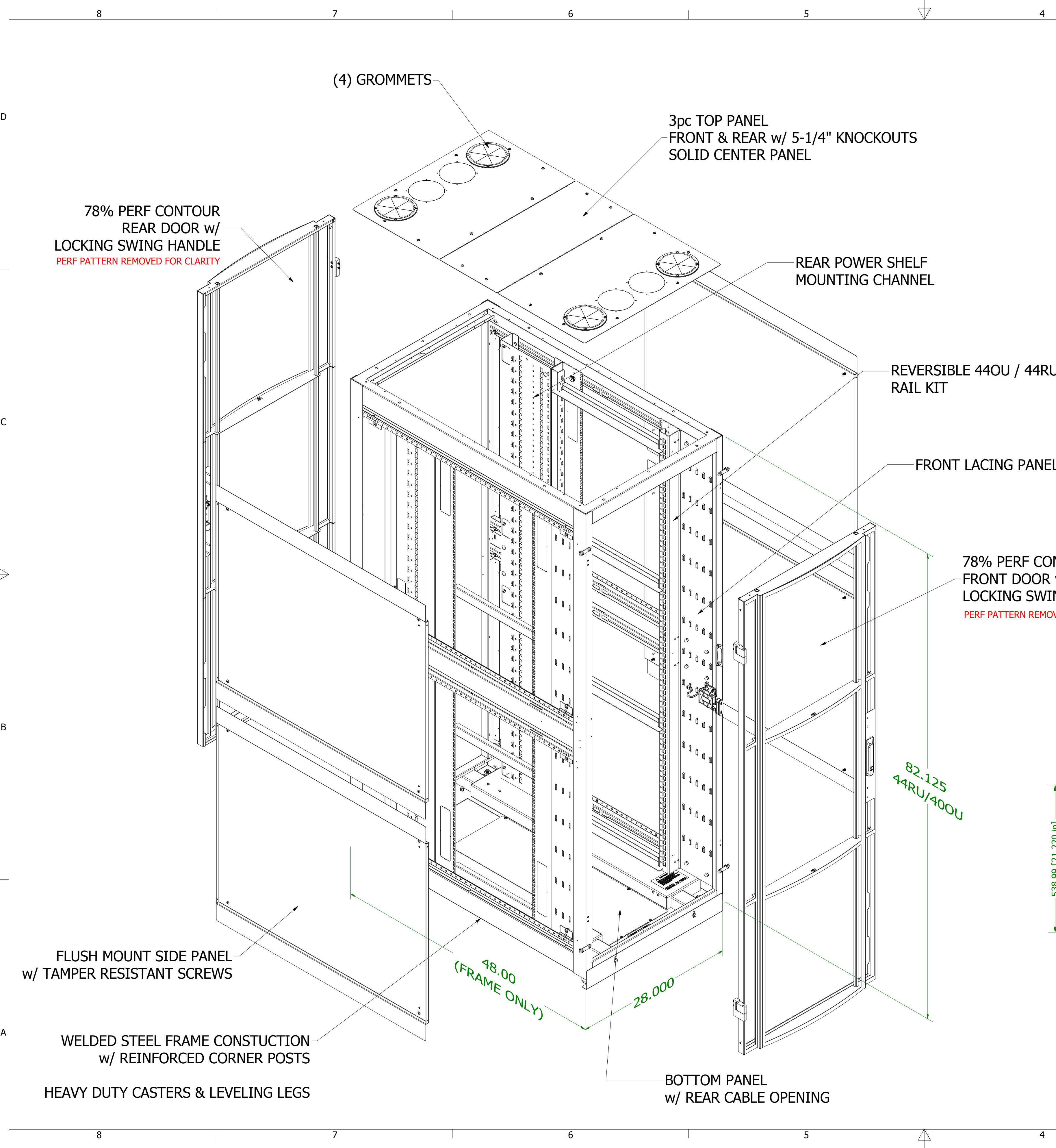

BELDEN			
THIS DRAWING AND ALL INFORMATION CONTAINED HEREIN IS THE PROPERTY OF BELDEN. ANY USE, COPY OR REPRODUCTION OF THIS MATERIAL WITHOUT WRITTEN PERMISSION OF BELDEN IS PROHIBITED.			
OPEN BRIDGE RACK / XFI44U2848-S004			
APPROVED BY:	RCG	DRAWING AUTHOR:	RCG
APPROVAL DATE:	11/15/17		
UNITS:	INCH	Sheet 1 of 1	D
SCALE:	1:8	DATE	11/15/2017
			SUBMITTAL

REV	DESCRIPTION	BY	DATE